

COIL: @ 25°C

WINDING # 1

675 ±10% OHMS

13.5 VDC MUST OPERATE

2.3 VDC Must Release

WINDING # 2

OHMS

MUST OPERATE

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's


SHOCK 100 g's 6 ± 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

# CUSTOMER DATA SHEET

TOLERANCE UNLESS OTHERWISE SPECIFIED  
DECIMALS ±.005 FRACTIONAL ± 1/64

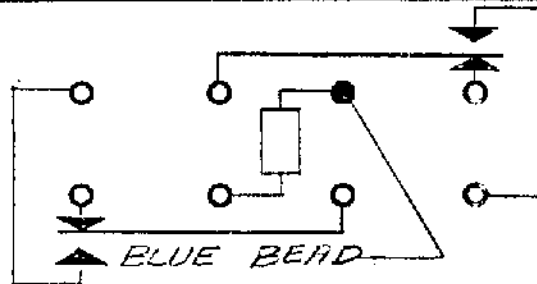

CONTACT RATING:  
2A @ 28VDC RESISTIVE

DR. 4/12/83

CK. OSW



Communications  
Instruments, Inc.

CUST. M5757/10-043

CUST. NO. SPL

TYPE "FW" RELAY

FW 1106G06

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[FW1106G06](#)