


COIL: @ 25° C
 RESISTANCE 200 OHMS ± 10%
 NOMINAL VOLTAGE 12.6 VDC
 MUST OPERATE 6.8 VDC
 MUST RELEASE .74 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE TIME 5 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

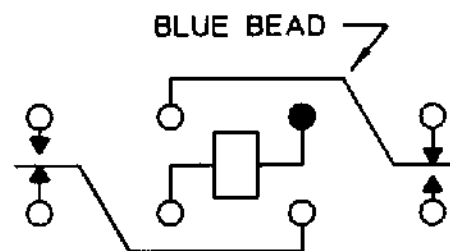

CONTACT RATING: LOW LEVEL TO 3 AMPS
RESISTIVE 28 VDC 100,000 OPERATIONS

DR. R.B. 5/24/94 CK 8/25/04 JAB

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C.I.I. STD.
 CUST. NO.

TYPE ***FW*** RELAY

FW1120D00

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[FW1120D00](#)