


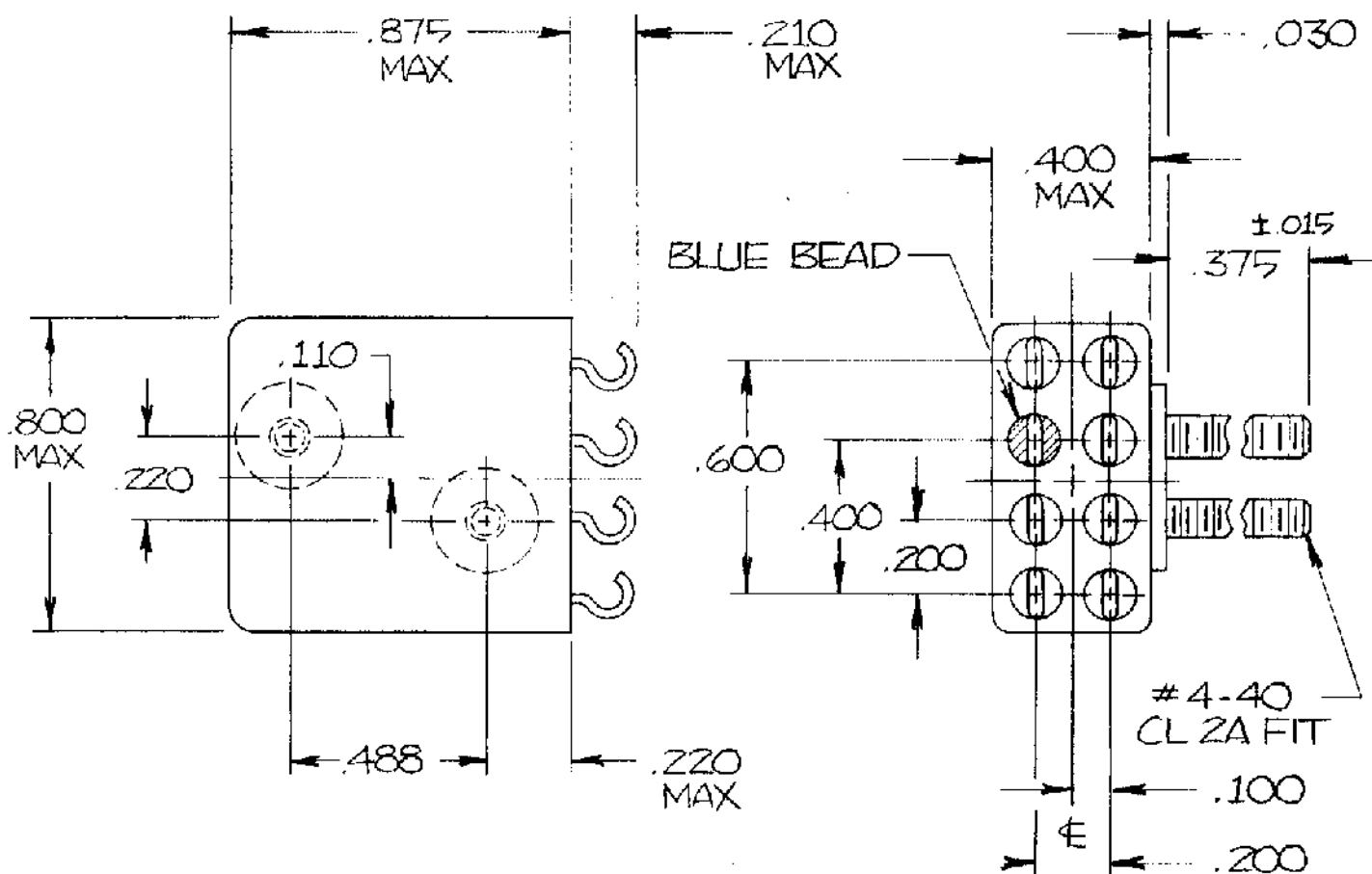

COIL:

RESISTANCE 675 Ω $\pm$ 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 2.3 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 2000 CPS @ 20 g's

SHOCK 100 g's 6 MS.DURATION

TEMPERATURE -65° °C TO +125° °C

NOTES:

CUSTOMER DATA SHEET

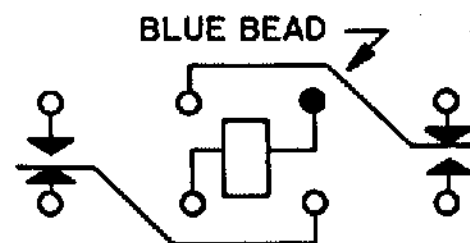

CONTACT RATING: 2A 28 VDC
RESISTIVE 100,000 OPERATIONS

DR. R.B. 1-18-90 CK. 1/8/90



Communications
Instruments, Inc.

CUST. QPL
CUST. NO. M5757/10-015

TYPE "FW" RELAY

FW1167G03

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[FW1167G03](#)