


COIL: @ 25°C  
 RESISTANCE 675 OHMS ± 10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 13.5 VDC  
 MUST RELEASE 1.47 VDC

ENVIRONMENT:  
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 5 MS MAX  
 RELEASE 5 MS MAX  
 BOUNCE 2 MS MAX

# CUSTOMER DATA SHEET

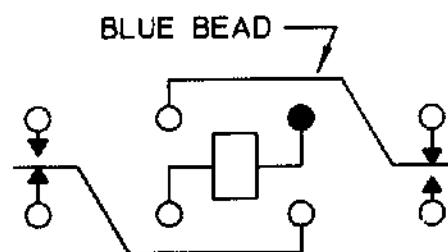

CONTACT RATING: LOW LEVEL TO 5A  
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 11/8/94 CK. 11/8/94

COMMUNICATIONS  
 INSTRUMENTS, INC.

CUST. C. I. I. STD.  
 CUST. NO.

TYPE FW5A RELAY

FW5A1201G00

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[FW5A1201G00](#)