


REV. 1 11/20/97

COIL: @ 25°C
 RESISTANCE 1600 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 18.0 VDC
 MUST RELEASE

ENVIRONMENT:
 VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX
 RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

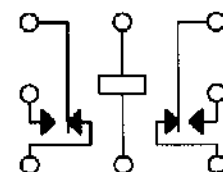

CONTACT RATING: LOW LEVEL TO 1 AMP
 28 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. R.B. 10/10/96 CK *[Signature]* 11/21/97

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.
 CUST. NO.

TYPE "HC" RELAY

HC3-26B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HC3-26B](#)