


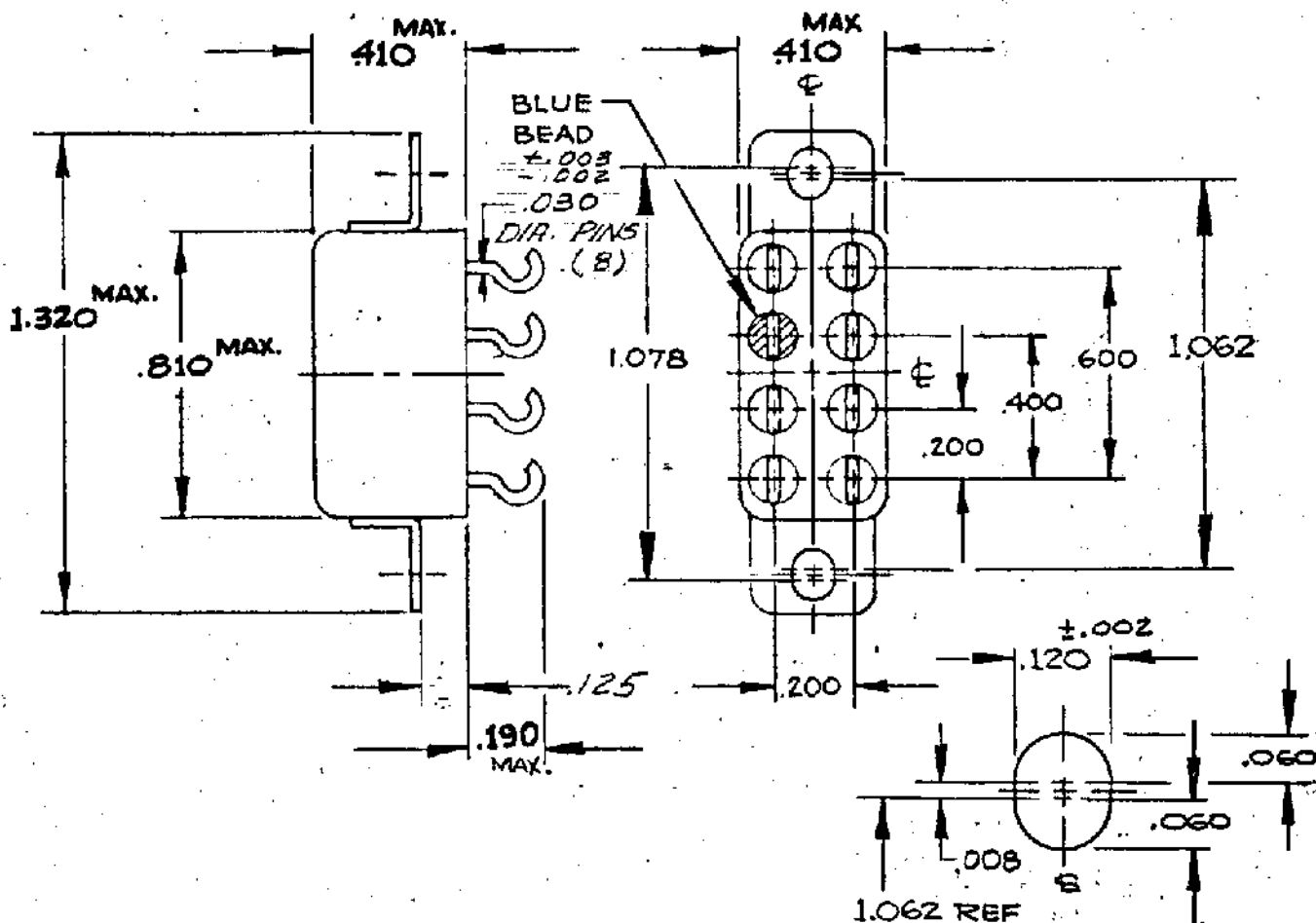

COIL: @ 25°C

RESISTANCE 160 OHMS ± 10%

NOMINAL VOLTAGE 12.0 VDC

MUST OPERATE 6.0 VDC

MUST RELEASE .7 - 4.0 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS AT 30 g's

SHOCK 100 g's 6 ± 1 MS DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

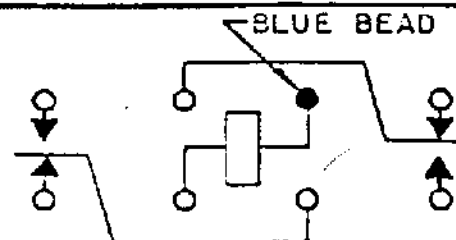

CONTACT RATING: LOW LEVEL TO 2 A @ 28 VDC 10000 OPERATIONS

DRB-18-86 JMB CK.

Communications Instruments, Inc.

CUST. QPL
CUST. NO. 139016/6-111 L

TYPE HFW RELAY

HFW 1130401

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1130G01](#)