

COIL: @ +25°C

RESISTANCE 700 OHMS ± 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 13.5 VDC

MUST RELEASE 15-28.0 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS AT 30 g's

SHOCK 100 g's 6 ± 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

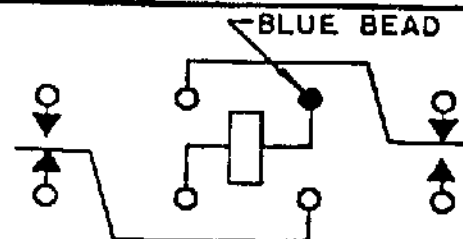

CONTACT RATING: Low Level

2 AMPS, 28 VDC 100,000

Operations

DR8-18-86 JMB

CK.



Communications
Instruments, Inc.

CUST.

CUST. NO. 039016/6-1044

TYPE HFW RELAY

HFW 1130K06

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1130K06](#)