

COIL: @ 25°C

RESISTANCE 40 OHMS \pm 10%

NOMINAL VOLTAGE 6.0 Vdc

MUST OPERATE 3.2 Vdc

MUST RELEASE .35 Vdc

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS AT 100 g's


SHOCK 65 g's 11 \pm 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: RELAY IS RATED FOR GROUNDED CASE

APPLICATION

CUSTOMER DATA SHEET

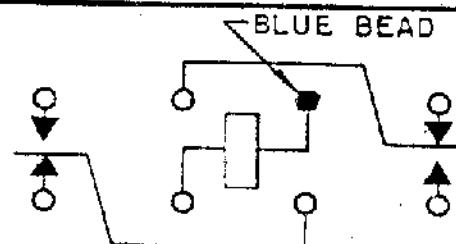

CONTACT RATING: 2 A @ 28 Vdc, .3 A @ 115 Vac, .75 A @ 28 Vdc

(.200 HENRY), LOW LEVEL

10-50 μ A @ 10-50 mVdc

DR. 01-12-82

CK. JAL



Communications
Instruments, Inc.

CUST. QPL
CUST. NO. M39016/6-123L

TYPE HFW RELAY

HFW 1201 F01

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1201F01](#)