

COIL: @ 25°C

RESISTANCE 160 OHMS ± 10%

NOMINAL VOLTAGE 12.0 VDC

MUST OPERATE 6.0 VDC

MUST RELEASE .7 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 2000 CPS AT 20 g's

SHOCK 100 g's 6 ± 1 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES:

CUSTOMER DATA SHEET

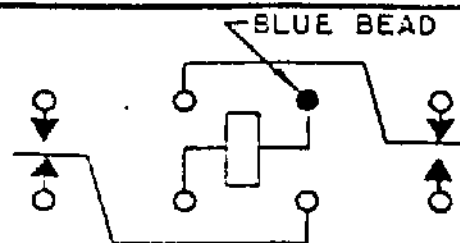

CONTACT RATING: LOW LEVEL TO
2 A @ 28 VDC

DR. 1-23-84

CK. OSW



Communications
Instruments, Inc.

CUST. GPL
CUST. NO. 39016/6-216L

TYPE HFW RELAY

HFW 1201G02

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1201G02](#)