

REV. 1  
DCO 16124

COIL: @ +25 °C  
 RESISTANCE 27 OHMS ± 10%  
 NOMINAL VOLTAGE 5.0 VDC  
 MUST OPERATE 2.7 VDC  
 MUST RELEASE 1.65 VDC MAX, 0.29 VDC MIN.


ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX  
 CONTACT BOUNCE 2 MS MAX  
 ALL OTHER REQUIREMENTS TO MIL-R-39016 LEVEL L

CUST. QPL  
 CUST. NO. M39016/6-139L

TYPE "HFW" RELAY

## CUSTOMER DATA SHEET

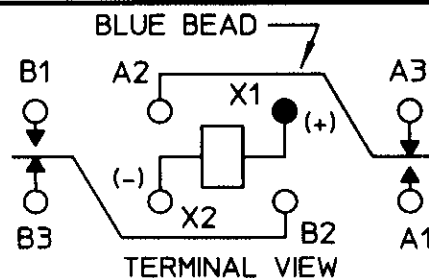

CONTACT RATING: LOW LEVEL TO  
 2 AMPS 28 VDC RESISTIVE  
 100,000 OPERATIONS

DR. R.B. 5/29/96 CK. G/H 2/21/00

COMMUNICATIONS  
 INSTRUMENTS, INC.

HFW1201L01

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1201L01](#)