



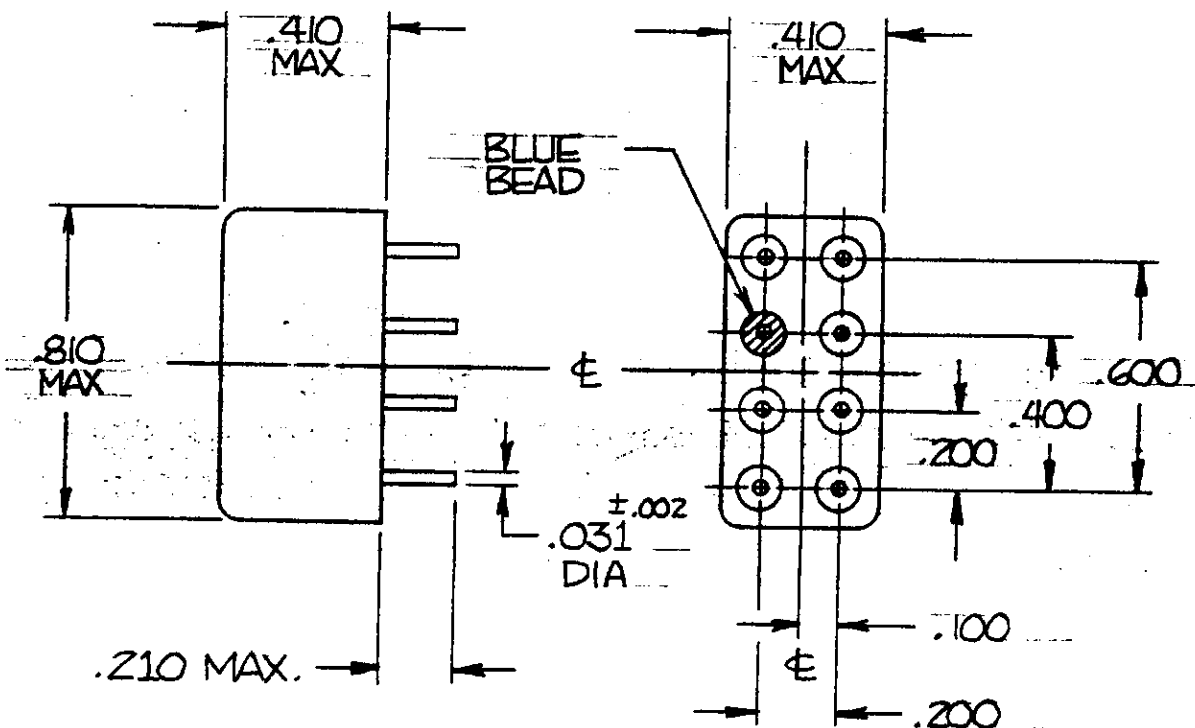

COIL: @ 25°C
 RESISTANCE 218 Ω $\pm 10\%$
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 9.2 VDC
 MUST RELEASE _____

CUSTOMER DATA SHEET

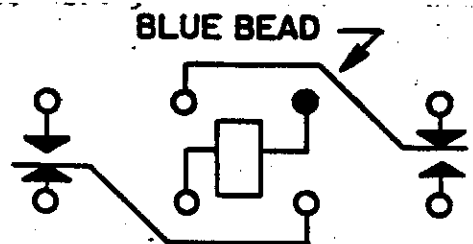

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 MS.DURATION
 TEMPERATURE -45 °C TO +70 °C

CONTACT RATING: 2A RESISTIVE
28 VDC 100,000 OPERATIONS

NOTES: OPERATE TIME 5 MS MAX
RELEASE TIME 3 MS MAX
500VAC DIELECTRIC ALL POINTS

DR. R.B. 1-25-91 CK. 1/25/91 JMB



Communications
Instruments, Inc.

CUST. P & B
 CUST. NO. HPS-11D-12

TYPE HFW RELAY

HFW1201S168

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1201S168](#)