


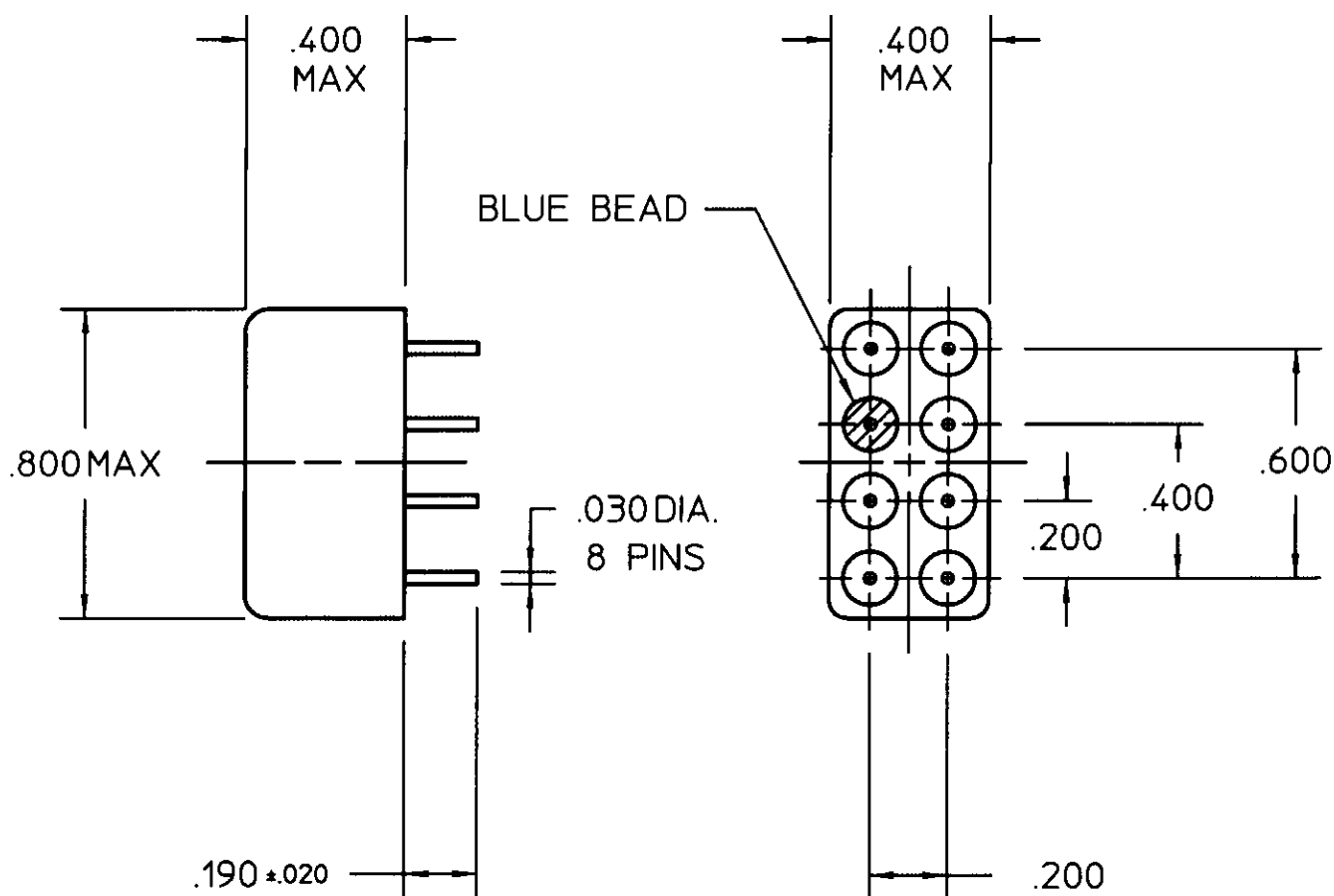

REV. 0

DCO 15703

COIL:


RESISTANCE 1030 OHMS ±10%
 NOMINAL VOLTAGE 24.0 - 35.0 VDC
 MUST OPERATE 16.0 VDC
 MUST RELEASE 9.6 VDC MAX., 1.8 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 11 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 6 MS MAX.
RELEASE 5 MS MAX.
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

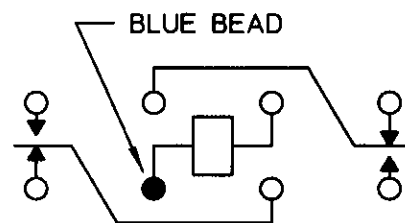

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMPS 28 VDC RESISTIVE
100,000 OPERATIONS

DR. B.D. 6/11/99 CK. *Bq#* 6-11-99



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. GENICOM
 CUST. NO. 3SAV5004K1

TYPE "HFW" RELAY

HFW1201S183

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW1201S183](#)