

REV. 1

DCO 144002


COIL: @ 25°C	
RESISTANCE	700 OHMS ±10%
NOMINAL VOLTAGE	26.5 VDC
MUST OPERATE	13.5 VDC
MUST RELEASE	1.5 VDC

ENVIRONMENT:

VIBRATION 10 Hz TO 2000 Hz @ 20 g's
 SHOCK 100 g's 6 ±1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 4 MS MAX.
 CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

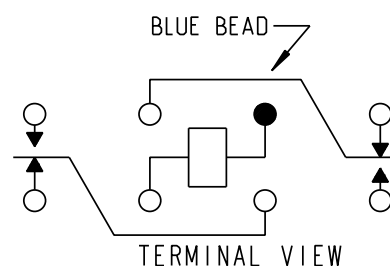

CONTACT RATING: LOW LEVEL TO 5A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 06DEC2004

CK. JMB 2/10/05

CII Technologies
 advanced control electronic solutions

CUST. C.I.I. STD.

CUST. NO. REV.

"HFW 5A" RELAY

HFW 5A1301K00

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HFW5A1301K00](#)