

REV 2 11/21/97

COIL:


RESISTANCE 1560 OHMS \pm 10%

NOMINAL VOLTAGE 26.5 VDC

MUST OPERATE 17.0 VDC

MUST RELEASE

CUSTOMER DATA SHEET

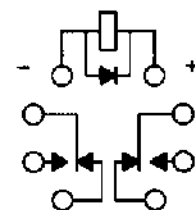

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's

SHOCK 30 g's 6 MS. DURATION

TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX.
RELEASE TIME 6.0 MS MAX.

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 4/6/92 CK ~~ERRY~~ 11/21/97

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C I. I. STD.

CUST. NO.

TYPE HMD RELAY

HMD-26B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1-1617108-3](#)