

REV. 0  
DCO 141811


COIL: @ 25°C  
RESISTANCE 1560 OHMS  $\pm$ 10%  
NOMINAL VOLTAGE 26.5 VDC  
MUST OPERATE 14.2 VDC  
MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
SHOCK 75 g's 6 MS. DURATION  
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX  
RELEASE TIME 4.0 MS MAX  
CONTACT STABILIZATION 2.5 MS MAX

CUSTOMER DATA SHEET

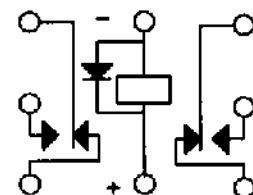

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP  
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 2/23/00



COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. OPL  
CUST. NO. M39016/18-036P REV.

'JMGAD' RELAY

JMGACD-26P

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMGACD-26P](#) [1-1617146-4](#)