


REV, 2 8/25/98

COIL: @ 25°C  
 RESISTANCE 1560 OHMS ± 10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 14.2 VDC  
 GATE TURN-ON 4.3 VDC MAX.  
 GATE TURN-OFF 0.5 VDC MAX.  
 MUST RELEASE 8.0 VDC MAX, 1.30 VDC MIN.

ENVIRONMENT:  
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
 SHOCK 75 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.5 MS MAX.  
 RELEASE TIME 4.0 MS MAX.  
 CONTACT STABILIZATION 2.0 MS MAX.

## CUSTOMER DATA SHEET

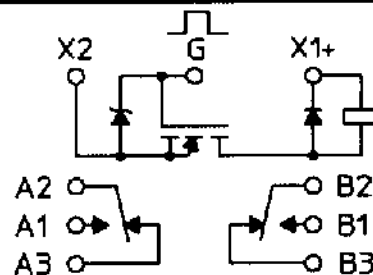

CONTACT RATING: LOW LEVEL TO 1A  
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/5/97 *(Signature)* 8/25/98

**COMMUNICATIONS  
 INSTRUMENTS, INC.**

CUST. GPL  
 CUST. NO. M28776/6-006M

TYPE JMGAT RELAY

**JMGAT-26M**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMGAT-26M](#)