

REV. 0  
DCO 140857


COIL: @ 25°C  
RESISTANCE 3200 OHMS  $\pm$  10%  
NOMINAL VOLTAGE 26.5 VDC  
MUST OPERATE 14.0 VDC  
MUST RELEASE 8.0 VDC MAX, 1.4 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's  
SHOCK 75 g's 6 MS. DURATION  
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX  
RELEASE TIME 2.5 MS MAX  
CONTACT STABILIZATION TIME 2.5 MS MAX

CUSTOMER DATA SHEET

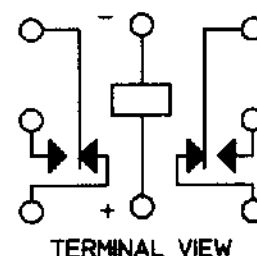

CONTACT RATING: LOW LEVEL TO 1 AMP  
28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 1/19/99 CK. ERY 1/20/99

COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. QPL  
CUST. NO. M39016/41-036M

TYPE JMGS RELAY

JMGSC-26M

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMGSC-26M](#) [1617149-5](#)