

REV. 0

DCO 141034

COIL:

RESISTANCE 11,000 OHMS ± 10%
 NOMINAL VOLTAGE 48.0 VDC
 MUST OPERATE 25.8 VDC
 MUST RELEASE 13.0 VDC MAX, 2.4 VDC MIN.


ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
 RELEASE TIME 7.5 MS MAX
 CONTACT STABILIZATION 2.5 MS MAX.

CUSTOMER DATA SHEET

TERMINAL VIEW

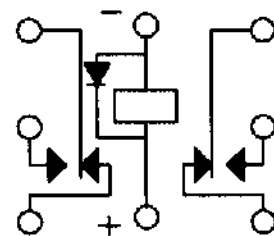

CONTACT RATING: LOW LEVEL TO 1 AMP
 28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. B.D. 4/28/99

CK 4/28/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/42-038P

TYPE JMGSD RELAY

JMGSCD-48P

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMGSCD-48P](#)