


REV. 1 8/25/98

COIL: @ 25°C
 RESISTANCE 3200 OHMS ± 10%
 NOMINAL VOLTAGE 26.5 VDC
 GATE TURN-ON 4.3 VDC MAX.
 GATE TURN-OFF 0.5 VDC MAX.
 MUST OPERATE 14.2 VDC
 MUST RELEASE 8.0 VDC MAX, 1.30 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.
 RELEASE TIME 7.5 MS MAX.
 CONTACT STABILIZATION 2.0 MS MAX.

CUSTOMER DATA SHEET

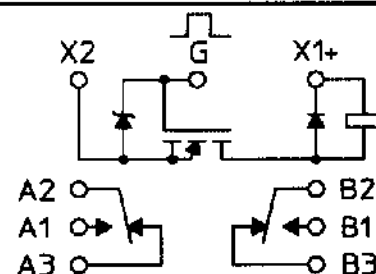

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 12/16/97 *ER. Vpey 8/25/98*

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. QPL
 CUST. NO. M28776/7-006M TYPE *MGST* RELAY

JMGST-26M

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMGST-26M](#)