


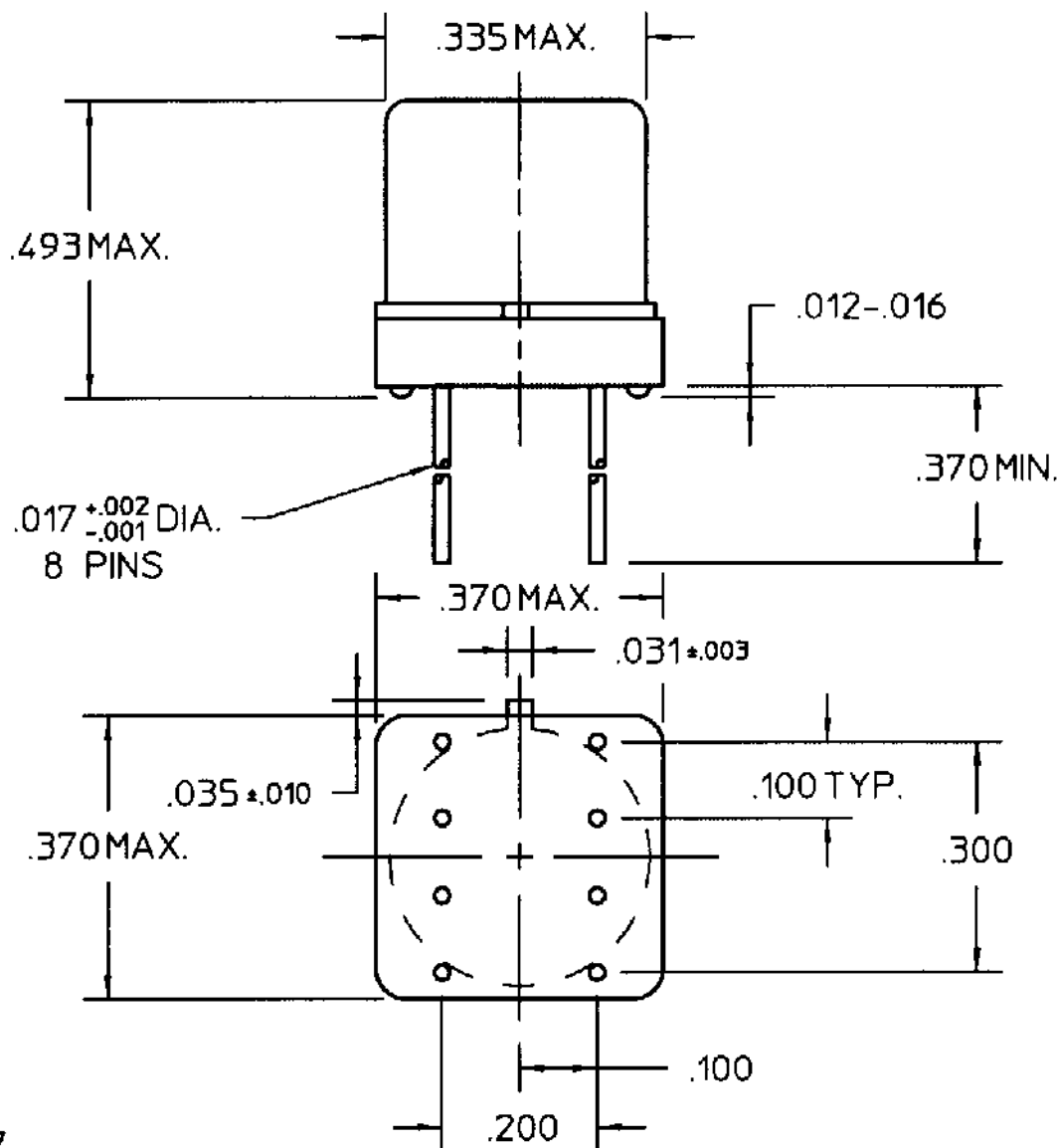

REV. 1
DCO 142087


COIL: @ 25°C
RESISTANCE 850 OHMS $\pm$ 10%
NOMINAL VOLTAGE 12.0 VDC
MUST OPERATE 7.0 VDC
MUST RELEASE 4.0 VDC MAX, 0.64 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
SHOCK 75 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 2.0 MS MAX
CONTACT BOUNCE 15 MS MAX

CUSTOMER DATA SHEET

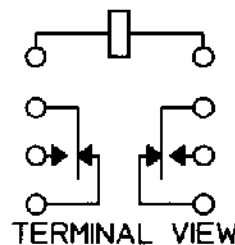

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. R.B. 10/3/95

CK. *John C* 6/8/00

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. OPL
CUST. NO. M39016/11-043L REV.

"JMS" RELAY

JMSC-12XLS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JM5C-12XLS](#)