

REV. 0

DCO 143159

COIL: @ 25°C

RESISTANCE 850 OHMS \pm 10%

NOMINAL VOLTAGE 12.0 VDC

MUST OPERATE 7.0 VDC

MUST RELEASE 4.0 VDC MAX., 0.64 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION


TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX.

RELEASE TIME 2.0 MS MAX.

CONTACT STABILIZATION TIME 2.0 MS MAX.

CUSTOMER DATA SHEET

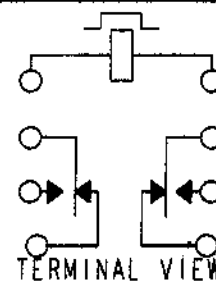

CONTACT RATING: LOW LEVEL TO
1A 28 VDC RESISTIVE 100,000
OPERATIONS

DR. B.D. 8/17/01

CK *[Signature]* 8/22/01

CII Technologies
advanced control electronic solutions

CUST. OPL

CUST. NO. M39016/J1-043P REV.

"JMS" RELAY

JMSC-12XPS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JM5C-12XPS](#)