

REV. 0

DCO 141210


COIL: @ 25°C
 RESISTANCE 1600 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 18.0 VDC
 MUST OPERATE 9.8 VDC
 MUST RELEASE 6.0 VDC MAX. 0.92 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
 RELEASE TIME 2.0 MS MAX
 CONTACT STABILIZATION 2.0 MS MAX

CUSTOMER DATA SHEET

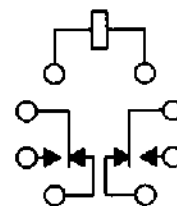

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 8/2/99

CK. *[Signature]*

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M39016/11-040P REV.

"JMS" RELAY

JMSC-18XP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMSC-18XP](#)