


REV. 0
DCO# 143078

COIL: @ 25°C
 RESISTANCE 100 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 2.6 VDC
 MUST RELEASE 1.4 VDC MAX, 0.23 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C
 NOTES: OPERATE TIME 4.0 MS MAX
 RELEASE TIME 2.0 MS MAX
 CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

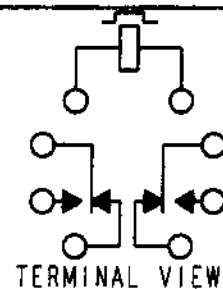

CONTACT RATING: LOW LEVEL TO 1A
 28VDC RESISTIVE 100,000 OPERATIONS

DR. BSH 07/09/01

Stamp 7/9/01

CII Technologies
 advanced control electronic solutions

CUST. OPL
 CUST. NO. M39016/11-033L REV. 0

"JMS" RELAY

JMSC-5XL

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMSC-5XL](#)