

COIL: @ 25°C
 RESISTANCE 64 OHMS \pm 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 2.9 VDC
 MUST RELEASE 2.2 VDC MAX, 0.8 VDC MIN.

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4 MS MAX
RELEASE TIME 75 MS MAX
CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

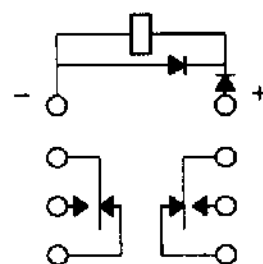

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 3/27/96 CK. 3/27/96

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. OPL
 CUST. NO. M39016/21-041L

TYPE JMSDD RELAY

JMSCDD-5XLS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMSCDD-5XLS](#)