

REV. 0

DCO 142958

COIL: @ 25°C
 RESISTANCE 3300 OHMS ±10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.2 VDC
 TURN -ON BASE CURRENT 0.06 mADC
 MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C


NOTES:

TURN-ON TIME 4.0 MS MAX

TURN-OFF TIME 7.5 MS MAX

CONTACT STABILIZATION TIME 2.0 MS MAX.

CUSTOMER DATA SHEET

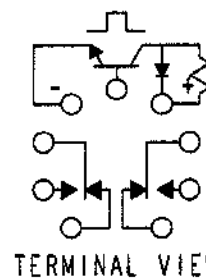

CONTACT RATING: LOW LEVEL TO 1A
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 5/31/01 CR. 5/31/01

CII Technologies
 advanced control electronic solutions

CUST. OPL
 CUST. NO. M28776/3-038P REV.

JMST RELAY

JMSCT-26XP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMSCT-26XP](#)