


REV. 0

DCO 144005

| | |
|-----------------|----------------------------|
| COIL: @ 25°C | |
| RESISTANCE | 3300 OHMS ±10% |
| NOMINAL VOLTAGE | 26.5 VDC |
| MUST OPERATE | 15.2 VDC |
| MUST RELEASE | 10.8 VDC MAX, 1.7 VDC MIN. |

| | |
|--------------|--|
| ENVIRONMENT: | |
| VIBRATION | 10 Hz TO 3000 Hz @ 30 g's |
| SHOCK | 75 g's 6 MS. DURATION |
| TEMPERATURE | -65 °C TO +125 °C |
| NOTES: | OPERATE TIME 4.0 MS MAX. |
| | RELEASE TIME 7.5 MS MAX. |
| | CONTACT STABILIZATION TIME 2.0 MS MAX. |

CUSTOMER DATA SHEET

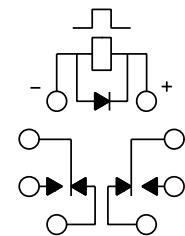

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 16FEB2005

CK. JERRY C. 2/17/05

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/21-012P REV.

"JMSDD" RELAY

JMSWDD-26XP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMSWDD-26XP](#)