


REV. 0
DCO 141001

COIL: @ 25°C
 RESISTANCE 850 OHMS \pm 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE VOLTAGE 7.4 VDC
 TURN-ON BASE CURRENT 0.12 mADC
 MUST RELEASE 4.0 VDC MAX, 0.63 VDC MIN.

ENVIRONMENT:
 VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 4.0 MS MAX
TURN-OFF TIME 7.5 MS MAX
CONTACT STABILIZATION TIME 2.0 MS MAX

CUSTOMER DATA SHEET

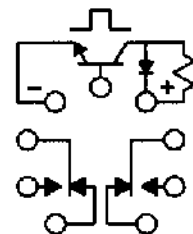

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 4/15/99 CK/era 4-15-99

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
 CUST. NO. M28776/3-020P

TYPE JMST RELAY

JMSWT-12XP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMSWT-12XP](#)