

REV. 0 DCO 140782

COIL: @ 25°C

RESISTANCE 1600 OHMS \pm 10%


NOMINAL VOLTAGE 18.0 VDC

MUST OPERATE VOLTAGE 10.0 VDC

TURN-ON BASE CURRENT 0.09 mADC

MUST RELEASE 6.0 VDC MAX, 0.91 VDC MIN.

CUSTOMER DATA SHEET

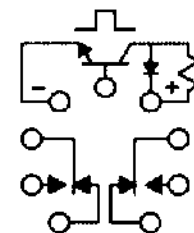

TERMINAL VIEW

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: TURN-ON TIME 4.0 MS MAX

TURN-OFF TIME 7.5 MS MAX

CONTACT STABILIZATION TIME 2.0 MS MAX

CONTACT RATING: LOW LEVEL TO 1A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 12/3/98 CK. Verma 12/4/98

COMMUNICATIONS
INSTRUMENTS, INC.

CUST. QPL
CUST. NO. M28776/3-021P

TYPE JMST RELAY

JMSWT-18XP

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[JMSWT-18XP](#)