

REV. 2

DCO 62982

COIL: @ 25°C

CUSTOMER DATA SHEET

SET

RESET

1150 OHMS ±10%

1150 OHMS ±10%

26.5 VDC NOMINAL VOLTAGE

26.5 VDC NOMINAL VOLTAGE

13.5 VDC MUST OPERATE

13.5 VDC MUST OPERATE

ENVIRONMENT:

VIBRATION 10 Hz 2000 Hz 30 g's


SHOCK 100 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 5 MS MAX.

CONTACT BOUNCE 2 MS MAX.

THIS COIL WILL ACTIVATE CONTACTS

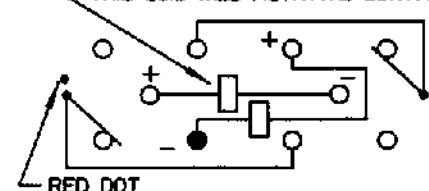

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 2A
28 VDC RESISTIVE 100,000 OPERATIONS

DR. R.B. 9/9/98

CK. 9/30/98 JYS



COMMUNICATIONS
INSTRUMENTS, INC.

CUST. C. I. I. STD.

CUST. NO.

TYPE "LF" RELAY

LF2149K00

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[LF2149K00](#)