


REV. 1 1/22/93

COIL: @ 25°C
 RESISTANCE 330 OHMS ± 10%
 NOMINAL VOLTAGE 12.0 VDC
 MUST OPERATE 6.1 VDC
 MUST RELEASE .61 VDC

ENVIRONMENT:
 VIBRATION 10 CPS TO 2000 CPS @ 20 g's
 SHOCK 100 g's 6 ± 1 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: _____

CUSTOMER DATA SHEET

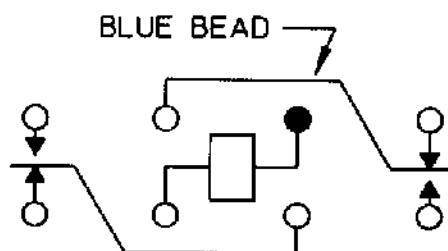

CONTACT RATING: LOW LEVEL TO
1 AMP 28 VDC RESISTIVE
100,000 OPERATIONS

DR. J.P. 10/19/87 CK. V2425018

**COMMUNICATIONS
 INSTRUMENTS, INC.**

CUST. C. I. I. STD.
 CUST. NO. _____

TYPE "MFW" RELAY

MFW1201K00

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[MFW1201K00](#)