

REV. 0  
DCO 15282


COIL: @ 25°C  
RESISTANCE 1500 OHMS ± 10%  
NOMINAL VOLTAGE 26.5 VDC  
MUST OPERATE 13.5 VDC  
MUST RELEASE 10.0 VDC MAX, 1.5 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 20 g's  
SHOCK 100 g's 6 ± 1 MS. DURATION  
TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE TIME 4 MS MAX.  
CONTACT BOUNCE 2 MS MAX.

CUSTOMER DATA SHEET

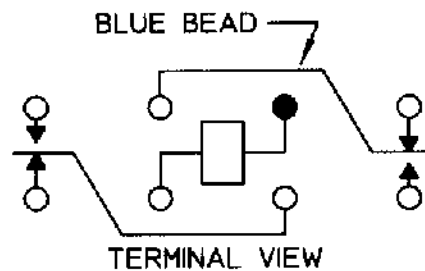

CONTACT RATING: LOW LEVEL TO  
1 AMP 28 VDC RESISTIVE  
100,000 OPERATIONS

DR. R.B. 4/8/99 CK. 4/9/99

COMMUNICATIONS  
INSTRUMENTS, INC.

CUST. QPL  
CUST. NO. M39016/34-012

TYPE 'MFW' RELAY

MFW1201N04

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[MFW1201N04](#)