


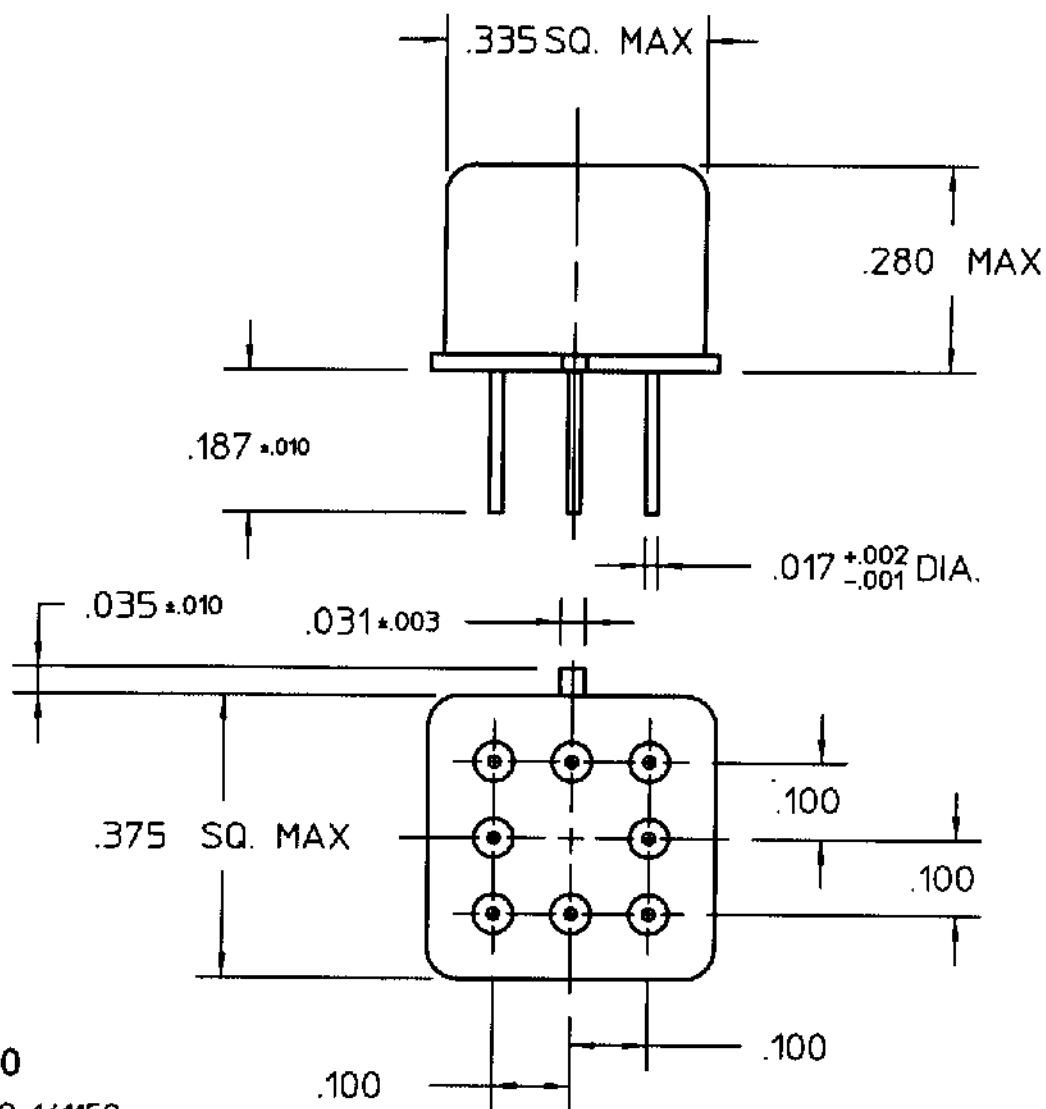

REV. 0

DCO 141159

COIL: @ 25°C
 RESISTANCE 1560 OHMS ±10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.2 VDC
 8.0 VDC MAX, 1.37 VDC MIN.
 MUST RELEASE

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 2.0 MS MAX

RELEASE TIME 1.5 MAX

CONTACT STABILIZATION 2.0 MS MAX

CUSTOMER DATA SHEET

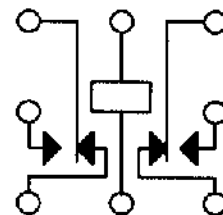

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
 28 VDC RESISTIVE 100,000 OPERATIONS

DR. B.D. 6/28/99 (CK) 6/28/99

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C.I.I.
 CUST. NO. COTS STD. REV.

PRMGA RELAY

PRMGAP-26Y

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[PRMGAP-26Y](#)