


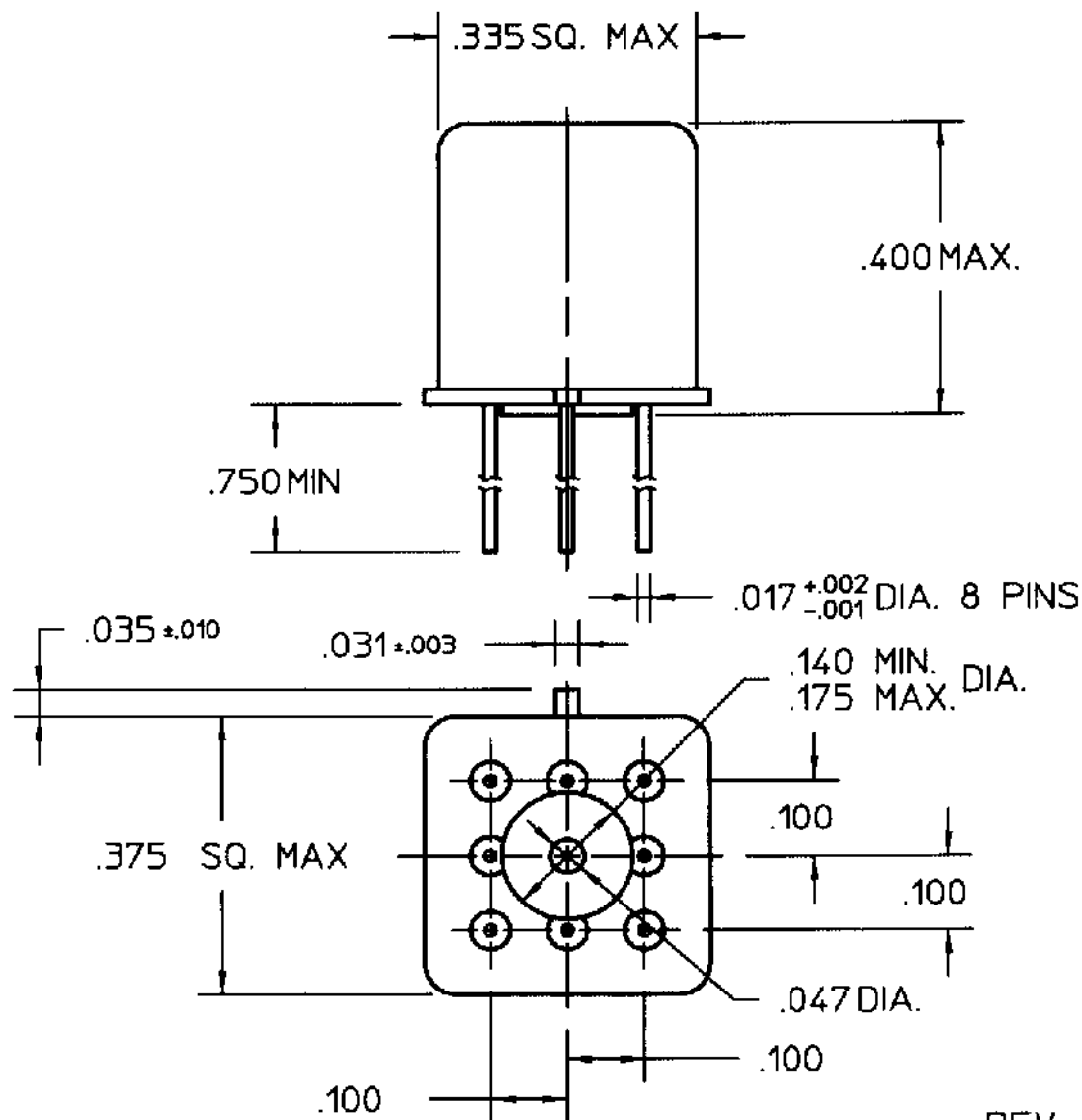

REV. 5 8/25/98

COIL: @ 25°C
 RESISTANCE 1600 OHMS ± 10%
 NOMINAL VOLTAGE 18.0 VDC
 MUST OPERATE 9.8 VDC
 MUST RELEASE 0.92 VDC

ENVIRONMENT:


VIBRATION 10 CPS TO 3000 CPS @ 30 g's

SHOCK 75 g's 6 MS. DURATION

TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE TIME 4.0 MS MAX
 RELEASE TIME 2.0 MS MAX
 CONTACT BOUNCE 1.5 MS MAX

CUSTOMER DATA SHEET

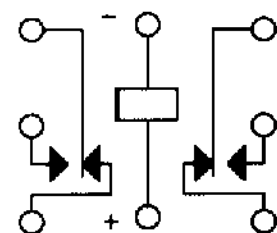

CONTACT RATING: LOW LEVEL TO 1 AMP
 28 VDC RESISTIVE 100,000 OPERATIONS MIN

DR. R.B. 5/29/97 *CK. YEPER 8/25/98*

COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C. I. I.
 CUST. NO. COTS STD.

TYPE PRMGSC RELAY

PRMGSC-18XW

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[PRMGSC-18XW](#)