


COIL: @ 25°C
 RESISTANCE 3200 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.0 VDC
 MUST RELEASE 8.0 VDC MAX, 1.37 VDC MIN.

ENVIRONMENT:

VIBRATION 10 CPS TO 3000 CPS @ 30 g's
 SHOCK 75 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE 4.0 MS MAX.
 RELEASE 7.5 MS MAX.
 CONTACT BOUNCE 1.5 MS MAX.

CUSTOMER DATA SHEET

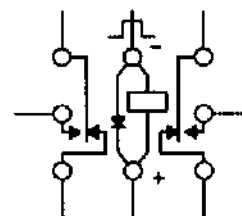

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO 1 AMP
 28 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. B.D. 9/20/99

ER. 9/23/99



COMMUNICATIONS
 INSTRUMENTS, INC.

CUST. C.I.
 CUST. NO. STANDARD REV.

SMGSD RELAY

SMGSD-26

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SMGSD-26](#)