

REV. 4
DCO 63333


COIL: @ 25°C
 RESISTANCE 390 OHMS ±10%
 NOMINAL VOLTAGE 26.5 VDC
 MUST OPERATE 14.0 VDC @ 25°C
 MUST RELEASE 1.4 VDC @ 25°C

ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's
 SHOCK 100 g's 6 MS. DURATION
 TEMPERATURE -65 °C TO +125 °C

NOTES: (LEVEL 1 ACCEPTANCE TESTING ONLY)
 OPERATE & RELEASE 7 MS MAX.
 (INCLUDING BOUNCE)

CUSTOMER DATA SHEET

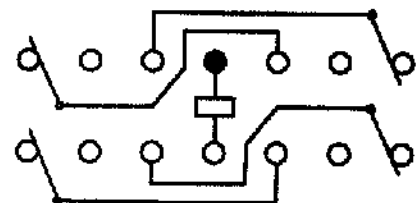

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
 2 AMP 28 VDC RESISTIVE

DR. R.B. 9/1/94

CK.TLG 10-24-00

CI Technologies
 advanced control electronic solutions

CUST. OPL
 CUST. NO. M39016/40-019 REV.

"SR" RELAY

SR-7619

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SR-7619](#)