


REV. A
DCO 143860

COIL: @ 25°C
RESISTANCE 100 OHMS ±10%
NOMINAL VOLTAGE 12.0 VDC
MUST OPERATE 6.5 VDC
MUST RELEASE 4.2 VDC MAX, 0.92 VDC MIN.

ENVIRONMENT:
VIBRATION 10 Hz TO 2000 Hz @ 15 g's
SHOCK 100 g's 6 MS. DURATION
TEMPERATURE -65 °C TO +125 °C
NOTES: OPERATE & RELEASE 7 MS MAX.
(INCLUDING BOUNCE)

CUSTOMER DATA SHEET

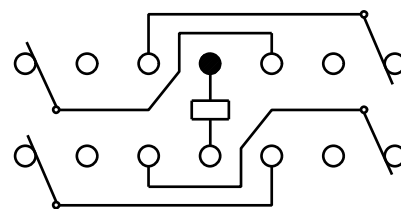

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO
2 AMP 28 VDC RESISTIVE
100,000 OPERATIONS

DR. B.D. 11MAR04 CK. J.M.B. 3/11/04

CII Technologies
advanced control electronic solutions

CUST. QPL
CUST. NO. M39016/40-010 REV.

"SR" RELAY

SR-7622

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SR-7622](#)