

REV. 0

DCO 64109

COIL: @ 25°C  
 RESISTANCE 390 OHMS ±10%  
 NOMINAL VOLTAGE 26.5 VDC  
 MUST OPERATE 13.0 VDC  
 MUST RELEASE 10.1 VDC MAX, 1.84 VDC MIN.


ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's  
 SHOCK 100 g's 6 MS. DURATION  
 TEMPERATURE -65 °C TO +125 °C

NOTES: OPERATE & RELEASE 7 MS MAX.

(INCLUDING BOUNCE)

CUSTOMER DATA SHEET

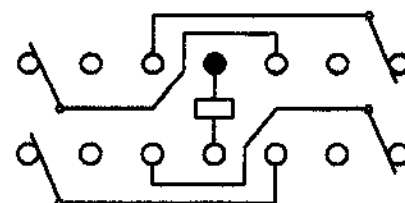

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO  
 2 AMP 28 VDC RESISTIVE  
 100,000 OPERATIONS

DR. PBB 7/20/01 CK: 7/20/01/pb

**CII Technologies**  
 advanced control electronic solutions

CUST. QPL  
 CUST. NO. M39016/40-025 REV.

"SR" RELAY

SR-7625

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SR-7625](#)