


REV. 3  
DCO 63333

COIL: @ 25°C  
RESISTANCE 390 OHMS ±10%  
NOMINAL VOLTAGE 26.5 VDC  
MUST OPERATE 14.0 VDC @ 25°C  
MUST RELEASE 1.4 VDC @ 25°C

#### ENVIRONMENT:

VIBRATION 10 CPS TO 2000 CPS @ 15 g's  
SHOCK 100 g's 6 MS. DURATION  
TEMPERATURE -65 °C TO +125 °C  
NOTES: TERMINALS ARE GOLD PLATED  
OPERATE & RELEASE 5 MS MAX.  
BOUNCE 5 MS MAX.

#### CUSTOMER DATA SHEET

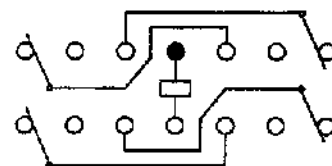

TERMINAL VIEW

CONTACT RATING: LOW LEVEL TO  
2 AMP 28 VDC RESISTIVE

DR. R.B. 11/29/90 CK. TUG 10-24-00

**CNI Technologies**  
advanced control electronic solutions

CUST. CII STD

CUST. NO. REV.

'SRBW' RELAY

SRBW-4C-24G

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[SRBW-4C-24G](#)