



Product Compliance


[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2024 (241) Candidate List Declared Against: JUNE 2024 (241) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Reflow solder capable to 260°C


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

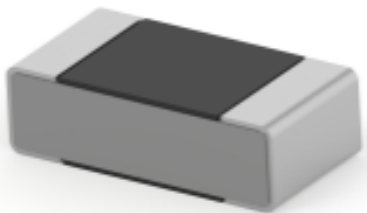

TE Part # 8-1879130-4
RN 0402 5K11 0.1% 10PPM 5K RL

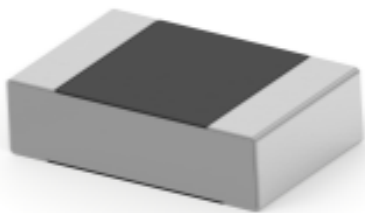

TE Part # 1-1676142-3
RN 0805 100K 0.01% 10PPM 5K RL



TE Part # 1614349-9
RN 0603 10K 0.1% 10PPM CUT LENGTH



TE Part # 1676153-2
RN 0805 10K 0.1% 10PPM 1KRL



TE Part # 1676153-3
RN 0805 10K 0.1% 10PPM 5KRL

Also in the Series | [Holsworthy RN73](#)



Surface Mount Resistors(3641)

Customers Also Bought




TE Part #1-1879226-9
CPF 1206 18K2 0.1% 25PPM 1K RL




TE Part #1676178-1
RN 0805 133R 0.1% 10PPM CUT LENGTH



TE Part #1623939-2
SC10-10-0549-10 1000UH AMMO 1000

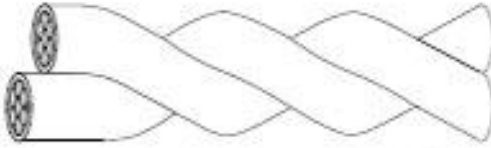


TE Part #841967-000
44A0121-14-6/9

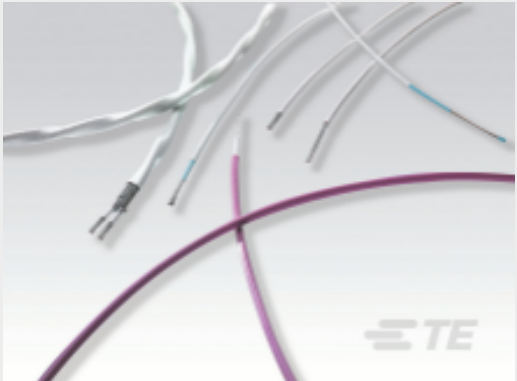

TE Part #1949923001
55A0131-26-0/1/4




TE Part #3180103004
55A0824-24-2/6

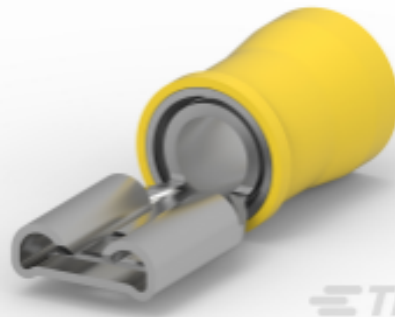


TE Part #8-1856388-6
Clip FASTON J 6,3x0,8 Lait eta



TE Part #2-1614354-2
RN 0603 590R 0.1% 10PPM CUT LENGTH

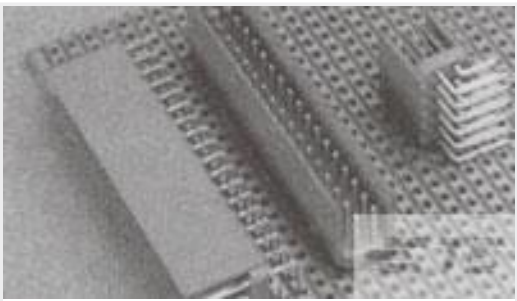

TE Part #281740-8
[HEADER HE13 STRAIGHT 2X8 P](#)

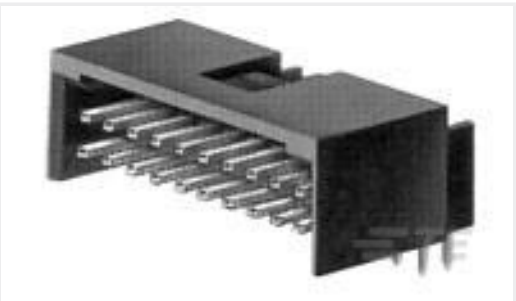

TE Part #103165-1
[10 MODII HDR DRRA 3/4SHRD .100](#)

Documents

CAD Files

3D PDF

3D

Customer View Model

[ENG_CVM_CVM_1676201-1_BC.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1676201-1_BC.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_1676201-1_BC.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

[1309350_PASSIVE_COMPONENT](#)

English

[High Precision Resistors \(SMD\) - Type RN73 Series - Tyco Electronics Passives](#)

English

[8-1773459-4_POWER_FILTERING_AND_RESISTIVE_SOLUTIONS_FOR_ELEVATORS_AND_ESCALATORS](#)

English

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1676201-1](#)