



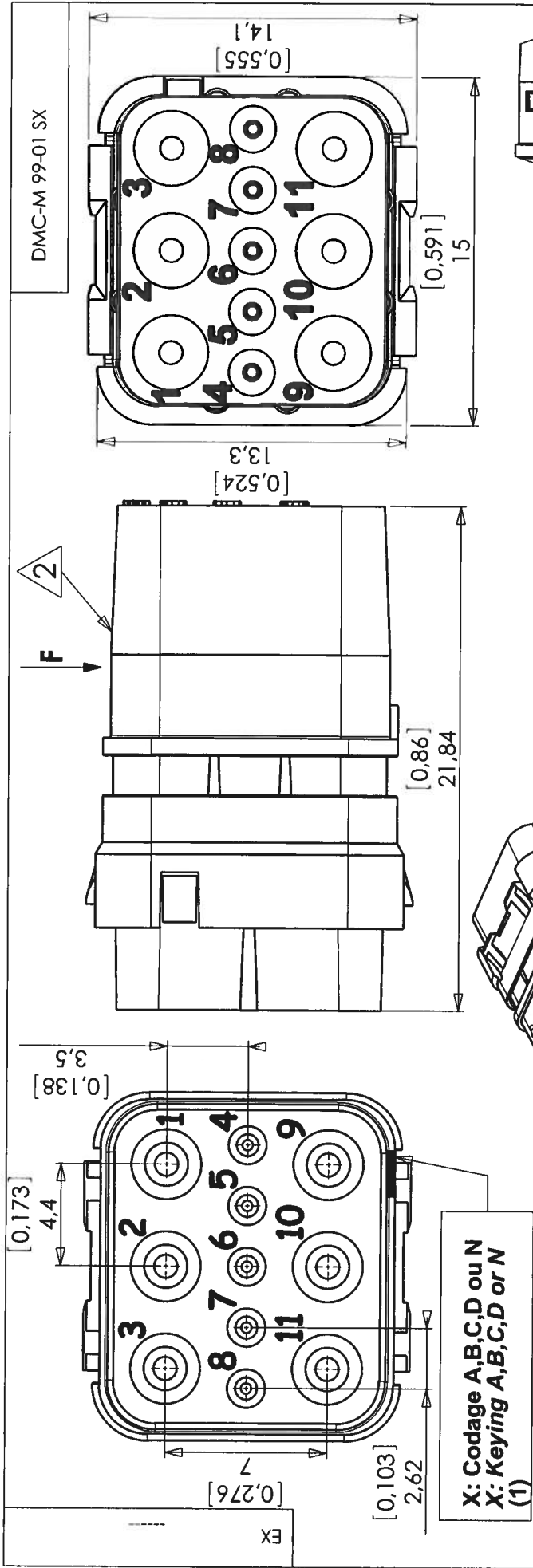


CARACTERISTIQUES:

Température d'utilisation: -55°C à +175°C
Matériaux: Thermoplastique, silicone fluoré
Masse: 3,7g Maxi (sans contact)
Dimensions: Millimètres [pouces]
Contacts: - 6 Contacts Femelle #16 SAE/AS 39029/57-358
- 5 Contacts Femelle #22 SAE/AS 39029/57-354

CHARACTERISTICS:

Operating temperature range: -55°C to +175°C
Materials: Thermoplastic and fluorosilicon
Weight: 3,7g Maxi (sans contact)
Dimensions: Millimeters [inches]
Contacts: - 6 Socket Contacts #16 SAE/AS 39029/57-358
- 5 Socket Contacts #22 SAE/AS 39029/57-354

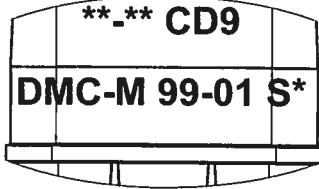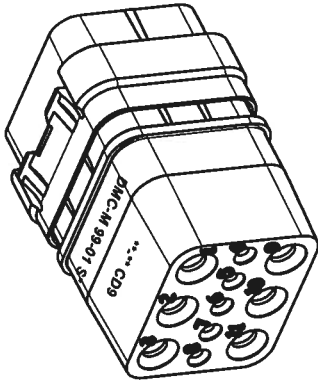

2 Marquages sur la face opposée aux clés.
Module livré avec contacts non montés / Module delivered with separate contacts

2 Marking on the opposite keys side.

Vue F
View F

REVISION	DATE	SERIE	DESIGNATION	DATE	DATE	VISA	VISA
a	09-06-09	OE120609	Module Femelle Hybride #16-#22 Socket Hybride Module #16-#22	27-03-06	27-03-06	Creation Created	Approval Approbation
ORIGINE :	DE017/06						

DEUTSCH	Connecteurs Electriques Deutsch	FICHE TECHNIQUE TECHNICAL DATA SHEET
17, rue LAVOISIER - BP 117 - 27091 EVREUX CEDEX 09 - FRANCE		
204-19-B/F00		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[ZPF000000000202100](#)