


PRESENTATION

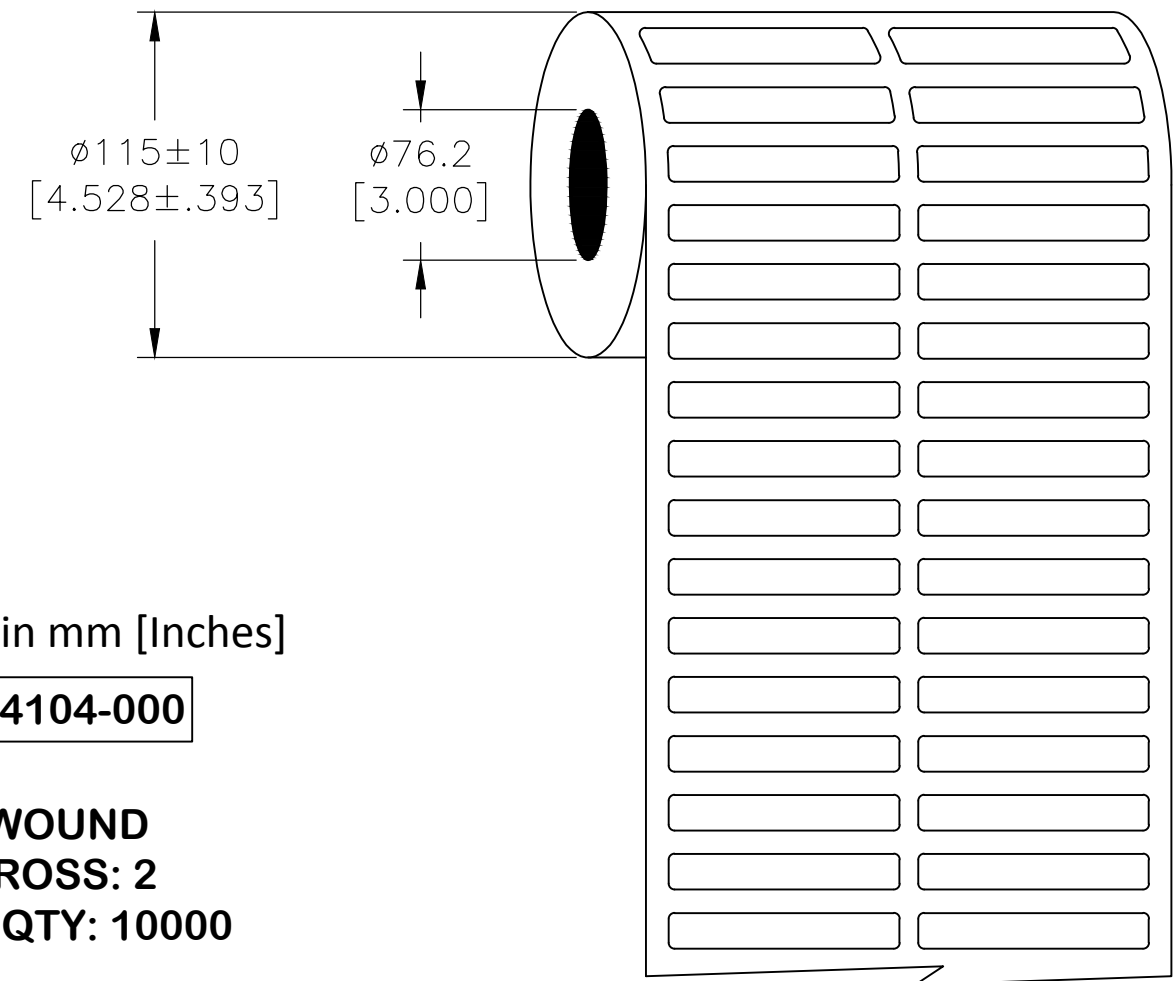

TE PN: E54104-000

**OUTSIDE WOUND
LABEL ACROSS: 2
PER ROLL QTY: 10000**

MATERIAL	METALIZED POLYESTER
ADHESIVE TYPE	PERMANENT
LINER	GLASSINE PAPER

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]*
HORIZONTAL REPEAT:	±0.8 [.031]*
PRINT POSITIONING:	±0.8 [.031]*
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

MATERIAL	SEE TABLE
----------	-----------

ANGLES	\pm
FINISH	

DWN	06JUL2021
M. NUTTALL	
CHK	06JUL2021
M. NUTTALL	
APVD	06JUL2021
A. KEAN	
PRODUCT SPEC	
TTDS-074	
APPLICATION SPEC	
—	
WEIGHT	0.013g
CUSTOMER DRAWING	

SIZE	CAGE CODE	DRAWING NO	RESTRICTED TO		
A3	C2290	C-MP-305047-10-8A	—		
		SCALE	NTS	SHEET	1 OF 1
				REV	B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[E54104-000](#)