
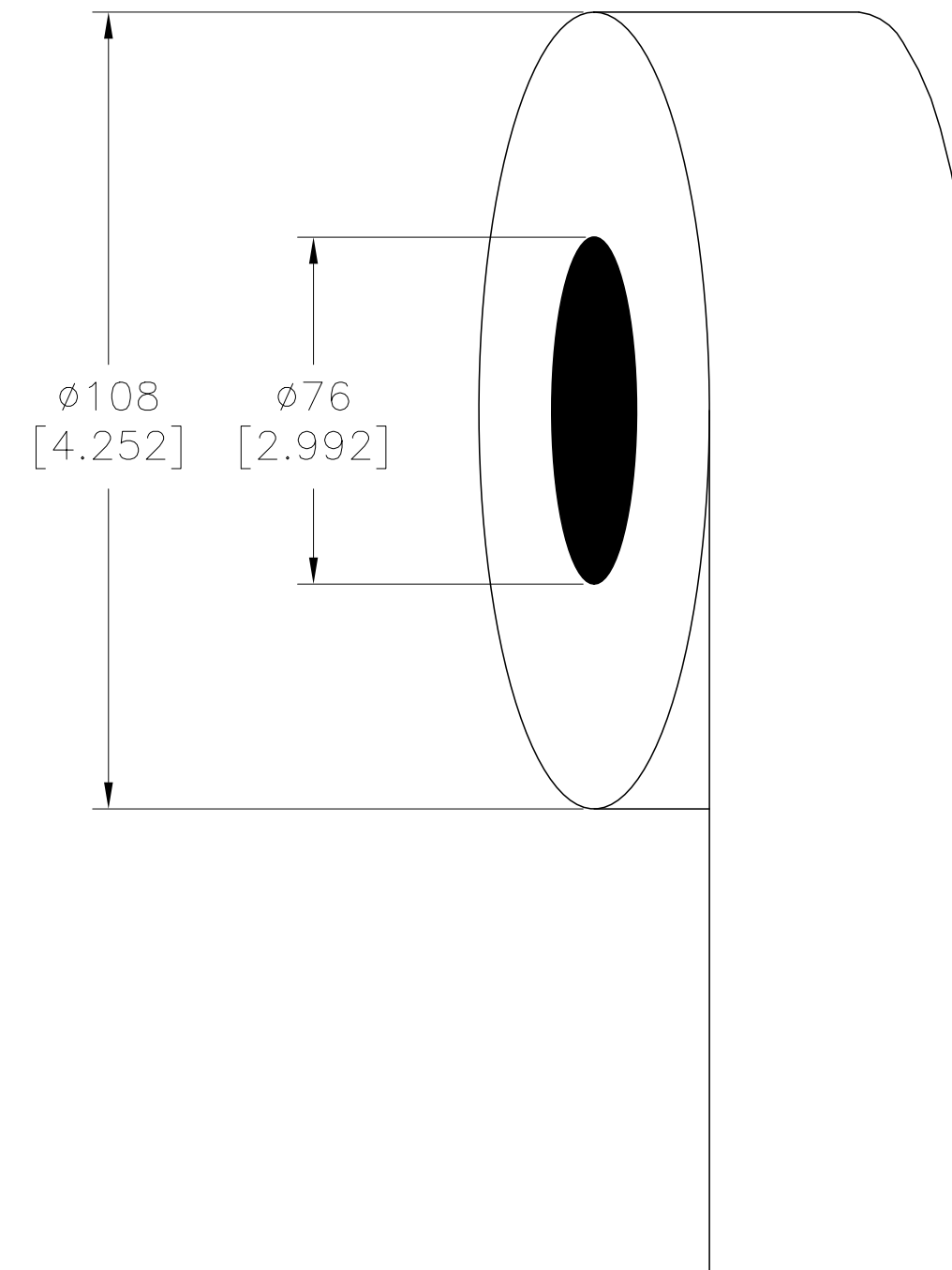


MATERIAL		POLYVINYL FLUORIDE (TEDLAR®)			
ADHESIVE TYPE		PERMANENT ACRYLIC			
LINEAR		WHITE KRAFT			
DWN GOPALAKRISHNA HV	31SEP2020			TE Connectivity	
CHK D.BURGAT	31SEP2020				
APVD D.BURGAT	31SEP2020	TEDLAR® LABEL – CLEAR – CONTINUOUS 38.1mm x 30.4m (1.5inch x 100ft) —			
PRODUCT SPEC					
TTDS-004					
APPLICATION SPEC		SIZE		RESTRICTED TO	
—		CAGE CODE		DRAWING NO	
WEIGHT		DRAWING NO		RESTRICTED TO	
77 g		A2 FB1U7		C=NPVF150CL-100	
CUSTOMER DRAWING		SCALE		SHEET	
		NTS		1 of 1	
				REV A	

 
PRESENTATION



OUTSIDE WOUND
LABEL ACROSS: 1
PER ROLL QTY: 30.48m / 100 feet

TE PN: F48039-001

TOLERANCES mm [INCH]	
LABEL HEIGHT:	±0.3 [.012]
LABEL WIDTH:	±0.3 [.012]
WEB WIDTH:	±0.8 [.031]
VERTICAL REPEAT:	±0.8 [.031]
HORIZONTAL REPEAT:	±0.8 [.031]
PRINT POSITIONING:	±0.8 [.031]
LEFT MARGIN:	±0.4 [.016]
QUANTITY:	-0 % +2 %
*NON ACCUMULATING	

THIS DRAWING IS A CONTROLLED DOCUMENT		
DIMENSIONS: mm [INCHES]		TOLERANCES UNLESS OTHERWISE SPECIFIED:
	0 PLC	\pm -
	1 PLC	\pm -
	2 PLC	\pm -
	3 PLC	\pm -
	4 PLC	\pm -
	5 PLC	\pm -
MATERIAL	FINISH	ANGLES
SEE TABLE		GLOSS

DWN	31SEP2020
GOPALAKRISHNA HV	
CHK	31SEP2020
D.BURGAT	
APVD	31SEP2020
D.BURGAT	
PRODUCT SPEC	
TTDS-004	
APPLICATION SPEC	
—	
WEIGHT	77 g
CUSTOMER DRAWING	

0		TE Connectivity	
0		NAME	
0		TEDLAR® LABEL – CLEAR– CONTINUOUS 38.1mm x 30.4m (1.5inch x 100ft) —	
SIZE	CAGE CODE	DRAWING NO	RESTRICTED TO
A2	FB1U7	C=NPVF150CL-100	—
SCALE		NITS	SHEET
		1	OF 1
		REV	A

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[F48039-001](#)