
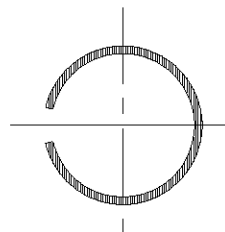


a) Part as supplied.

TSAS

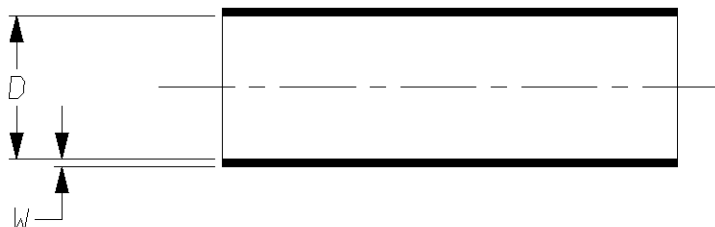

MATERIAL; FLEXIBLE HOT-MELT ADHESIVE.

COLOUR AMBER

CUT LENGTH AS PER ORDER

BROOKFIELD VISCOSITY AT 160°C 55 TO 85 Pas

TEMPERATURE RATING 125°C

DIMENSIONS (in millimetres)

PART No.	D	W
TSAS Nr.500	1.4±0.20	0.50±0.10
TSAS Nr.501	2.3±0.25	0.60±0.15
TSAS Nr.502	2.9±0.25	0.75±0.20
TSAS Nr.503	4.0±0.40	0.75±0.20
TSAS Nr.504	9.5±0.40	1.00±0.10

OBSOLETE

Copyright (!)

The copyright in this drawing is the property of Tyco Electronics UK Ltd. The drawing is issued on the condition that it is not copied, reproduced or disclosed to a third party, either in whole or in part without the prior written consent of Tyco Electronics UK Ltd.

Drawn A.LILLEY. Checked

Issue **7**

Date **11MAY11**

Conforms to ISO Recommendations

 
Approval

Design

MKTG.

Q.A.

3rd Angle Projection
Not to Scale



Raychem		Specification Control Drawing	Part Number TSAS Issue 7
Iss.	Date	E.C.R. No.	Details of Change
2	October 1979	****	Was proposal
3	September 1988	5332	D tollerance changed
4	September 1996	T0461	Additional comments added
5	August 1997	T1019	Temperature rating added
6	July 2006	CR06-DM-092	Size 504 added
7	11MAY11	ECR-10-026388	

Tyco electronics UK Ltd. Faraday Road, Swindon, Wiltshire, SN3 5HH England Telephone: (01793) 528171 Fax: 572516	Tyco electronics Corporation 300, Constitution Drive, Menlo Park, CA 94025 USA Telephone (650) 361-3860 Fax: (650) 361-5579
Cage Code K1010	Cage Code 06090

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[5672706013](#)