

REV. B
DCO 300859

TOLERANCES $\pm .010"$ - UNLESS
OTHERWISE SPECIFIED

COIL: @ 25°C
 RESISTANCE 290 OHMS $\pm 10\%$
 NOMINAL VOLTAGE 28 VDC
 MUST OPERATE 13.5 VDC MAX.
 MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.


ENVIRONMENT:
 VIBRATION 10 Hz TO 3000 Hz @ 30 g's
 SHOCK 200 g's 6 MS. DURATION
 TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 15 MS MAX.
 CONTACT STABILIZATION 2.5 MS MAX.
 CONTACT BOUNCE 1 MS MAX.

CUST. QPL
 CUST. NO. M83536/15-017M REV. ----

TE NUMBER
 1617754

CUSTOMER DATA SHEET

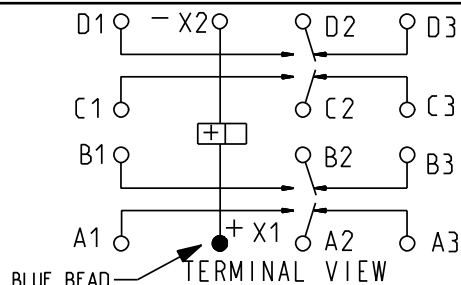

CONTACT RATING: LOW LEVEL
 10 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE
 100,000 OPERATIONS

DR. B.D. 16MAY2008 CK. J.M.B. 5/19/08

Tyco Electronics

©COPYRIGHT 2005
 TYCO ELECTRONICS CORPORATION
 ALL INTERNATIONAL RIGHTS RESERVED

CII PART NUMBER

FC A-410-1517M

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[M83536/15-017M](#)