

REV. 1 11/20/97


COIL: @ 25°C
 RESISTANCE 64 OHMS \pm 10%
 NOMINAL VOLTAGE 5.0 VDC
 MUST OPERATE 3.8 VDC
 MUST RELEASE _____

ENVIRONMENT:

VIBRATION 10 CPS TO 500 CPS @ 10 g's
 SHOCK 30 g's 6 MS. DURATION
 TEMPERATURE -55 °C TO +85 °C

NOTES: OPERATE TIME 4.0 MS MAX
RELEASE TIME 3.0 MS MAX

CUSTOMER DATA SHEET

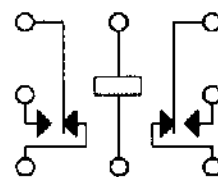

CONTACT RATING: LOW LEVEL TO 1 AMP
28 VDC RESISTIVE 100,000 OPERATIONS MIN.

DR. R.B. 9/8/93 *[Signature]*

**COMMUNICATIONS
INSTRUMENTS, INC.**

CUST. C. I. I. STD.
 CUST. NO. _____

TYPE "HC" RELAY

HC3-5B

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[HC3-5B](#)