
 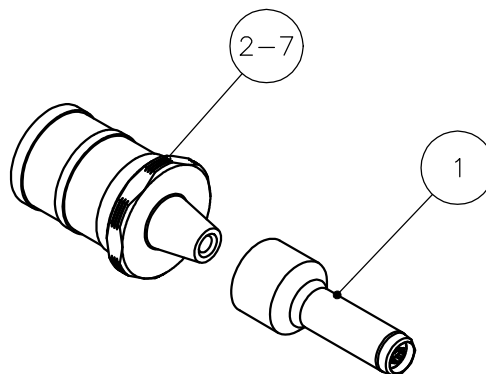




OBSOLETE

1			-	-	-	-	-	CRIMP BARREL HF6	-	-	8	50mm ² für hochflexibles Kabel
-	1		-	-	-	-	-	CRIMP BARREL HF6	-	-	7	70mm ²
-	-	1	-	-	-	-	-	CRIMP BARREL HF6	-	-	6	50mm ²
-	-	-	1	-	-	-	-	CRIMP BARREL HF6	-	-	5	35mm ²
-	-	-	-	1	-	-	-	CRIMP BARREL HF6	-	-	4	25mm ²
-	-	-	-	-	1	-	-	CRIMP BARREL HF6	-	-	3	16mm ²
-	-	-	-	-	-	1	-	CRIMP BARREL HF6	-	-	2	10mm ²
1	1	1	1	1	1	1	1	SET CONTACT PIN HF6	-	-	1	-

0-7	0-6	0-5	0-4	0-3	0-2	0-1	DESCRIPTION / BENENNUNG	MATERIAL	SURFACE COLOR	ITEM NO	NOTE / BEMERKUNG
							HF06.Sti.C.AG.10				
							HF06.Sti.C.AG.16				
							HF06.Sti.C.AG.25				
							HF06.Sti.C.AG.35				
							HF06.Sti.C.AG.50				
							HF06.Sti.C.AG.70				
							HF06.Sti.C.AG.50				

DIMENSIONS: MASSE/MAßSTÄBEN mm		DWN Schneider	10.04.03	MATERIAL —		FINISH —	
TOLERANCES UNLESS OTHERWISE SPECIFIED: ALLGEMEINTOLERANZEN n. ISO 9015 n. ISO 2768 - mH - E n. DIN 16901 - 14.0 0 PLC ± — 1 PLC ± — 2 PLC ± — 3 PLC ± — 4 PLC ± — ANGLES ± — 		CHK —	—	 TE Connectivity			
		APVD Braun	10.04.03				
		PRODUCT SPEC PRODUKTSPEZ. 108-74024	NAME Set contact pin & crimp barrel HF6 —				
		APPLICATION SPEC VERARBEITUNGSSPEZ. 114-74031					
		WEIGHT GEWICHT	SIZE A4	CAGE CODE 00779	DRAWING NO C-1103098	RESTRICTED TO —	
		CUSTOMER DRAWING				SCALE 1:1	SHEET 1 OF 1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1103098-4](#)