



| LOC | DIST | REVISIONS |     |             |           |     |      |  |
|-----|------|-----------|-----|-------------|-----------|-----|------|--|
|     |      | P         | LTR | DESCRIPTION | DATE      | DWN | APVD |  |
| E   | B    |           | BA  | NEW RELEASE | 05-AUG-09 | SM  | St.P |  |

FOR FURTHER INFORMATION SEE DATA SHEET FOR  
SERIES FC - HIGH POWER RESISTORS

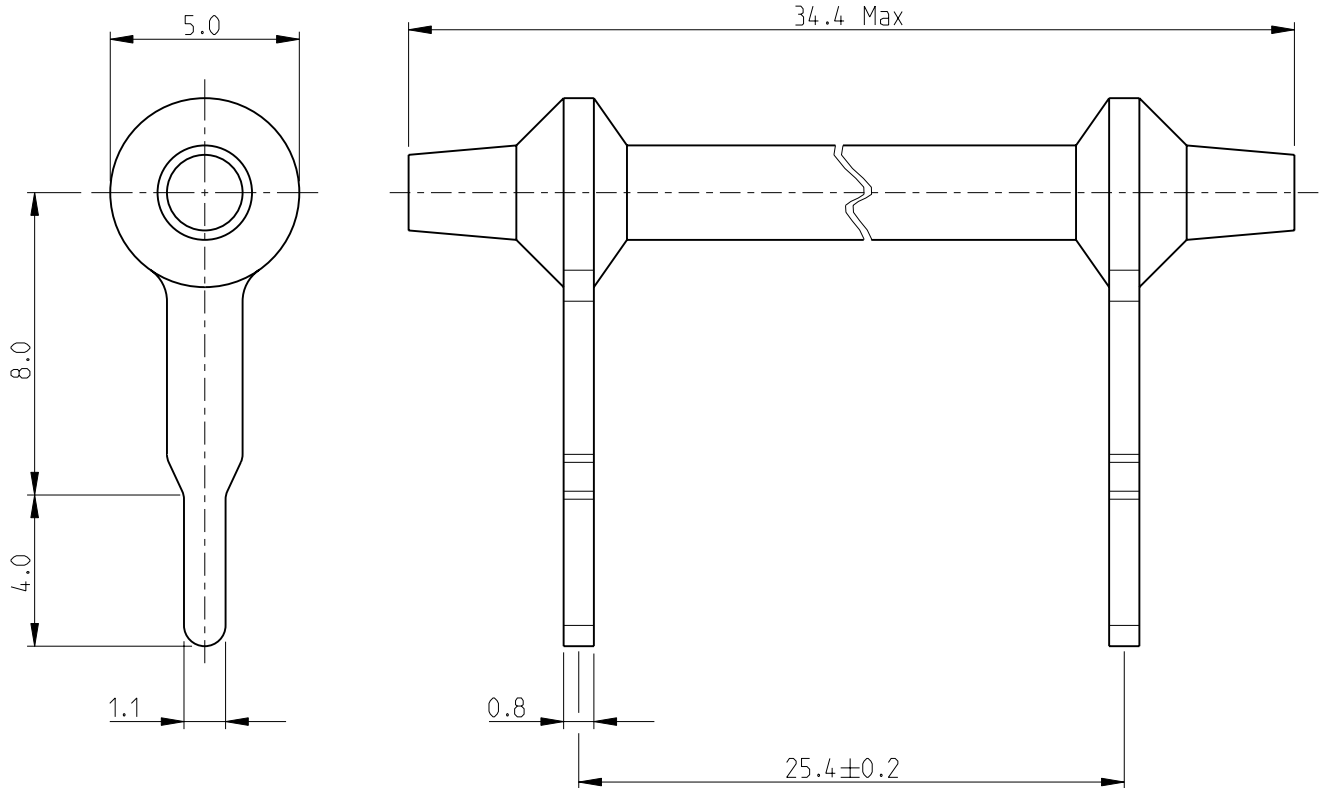

RoHS Compliant

SCALE 3:1

|  |  |                  |           |  |       |           |        |
|--|--|------------------|-----------|--|-------|-----------|--------|
| DIMENSIONS:                            |  | DWN              | 05-AUG-09 | MATERIAL   | -     | FINISH    | -      |
| mm                                     |  | SUBHASH.M        |           |  Tyco Electronics Corporation<br>Dorcan, Swindon, SN3 5HH |       |           |        |
| TOLERANCES UNLESS OTHERWISE SPECIFIED: |  | CHK              | 05-AUG-09 |  |       |           |        |
| 0 PLC ±0.5                             |  | ALLAN.P          |           |  |       |           |        |
| 1 PLC ±0.2                             |  | APVD             | 05-AUG-09 | NAME<br>HIGH POWER RESISTORS<br>SERIES FC6 (LOW PROFILE STANDOFF)  |       |           |        |
| 2 PLC ±0.1                             |  | STEPHEN.P        |           |  |       |           |        |
| 3 PLC ±-                               |  | PRODUCT SPEC     | -         | SIZE CAGE CODE DRAWING NO RESTRICTED TO  |       |           |        |
| 4 PLC ±-                               |  | APPLICATION SPEC | -         |  |       |           |        |
| ANGLES ±5°                             |  | WEIGHT           | -         | A 4  | 00779 | C-1623710 | -      |
| CUSTOMER DRAWING                       |  |                  |           | SCALE  | 5:1   | SHEET     | 1 OF 1 |
|  |  |                  |           | REV BA   |       |           |        |

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[1623710-3](#)