

Thermofit[®] Molded Parts
Specification Control Drawing
Limited Distribution

Part Number : 202A111-25-01/225
Description : Boot, Straight, Overexpanded

NOTES

- All dimensions are in $\frac{\text{inches}}{[\text{millimeters}]}$
- Dimensions appearing in table are as follows:
a - As Supplied
b - After Unrestricted Recovery
- Coating is optional. As supplied dimensions appearing in table are for uncoated parts. When coating is added, entry diameters will be reduced by .06 max.

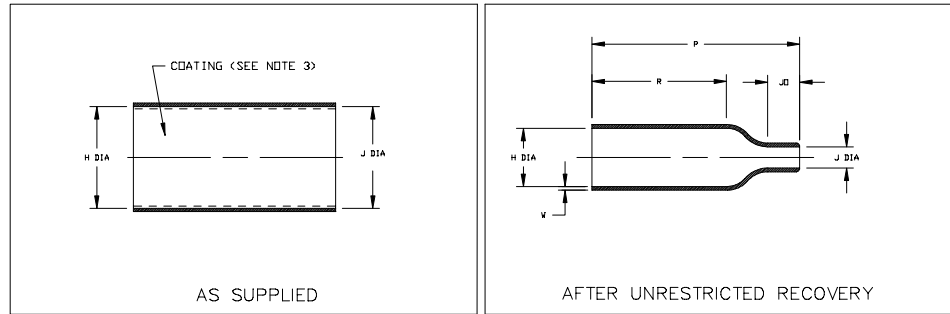


TABLE OF DIMENSIONS								
PART NUMBER	H		J		P	R	JO	W
	Min a	Max b	Min a	Max b	$\pm 10\%$ b	$\pm 10\%$ b	Ref b	$\pm 20\%$ b
202A111-25-01/225	.75 [19,0]	.31 [7,9]	.75 [19,0]	.15 [3,8]	1.00 [25,4]	.56 [14,2]	.23 [5,8]	.05 [1,27]

Raychem

RAYCHEM CORPORATION
300 CONSTITUTION DRIVE
MENLO PARK, CALIFORNIA 94025

Revision : A
Date : 4/21/99

Part Number : 202A111-25-01/225
Description : Boot, Straight, Overexpanded

Thermofit[®] Molded Parts
Specification Control Drawing
Limited Distribution

Part Number : 202A111-25-01/225
Description : Boot, Straight, Overexpanded

COMPATABILITY CHART					
MATERIAL DASH NO.	MATERIAL DESCRIPTION	RT SPEC	COATING SLASH NO.	COATING S NO.	COATING DESCRIPTION
-25	Elastomer, Fluid Resistant	RT-1325	/225	S-1206	Adhesive

ORDERING INFORMATION

Base part number 202A111 -25 -01 /225
Material dash number (See Compatability Chart)
Modification number (If necessary, see front of scd binder for a complete list)
Adhesive slash number (If necessary, see Compatability Chart)

THIS DRAWING IS SUBJECT TO CHANGE WITHOUT NOTICE; CONSULT YOUR NEAREST FIELD REPRESENTATIVE FOR CURRENT REVISION

Raychem

RAYCHEM CORPORATION
300 CONSTITUTION DRIVE
MENLO PARK, CALIFORNIA 94025

Revision : A
Date : 4/21/99

Part Number : 202A111-25-01/225
Description : Boot, Straight, Overexpanded

CAD FILE MP99085

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[814379N002](#) [EK4966-000](#) [679153-000](#) [725413-000](#) [CJ1952-000](#) [CN2148-000](#) [CN9033-000](#)