


These drawings and specifications are the property of Microdot Inc., are issued in strict confidence and shall not be divulged, be reproduced or copied, or used as the basis for the manufacture or sale of any article without written permission of Microdot Inc.

CDM 031-0049-0001 T.

CLASS 1

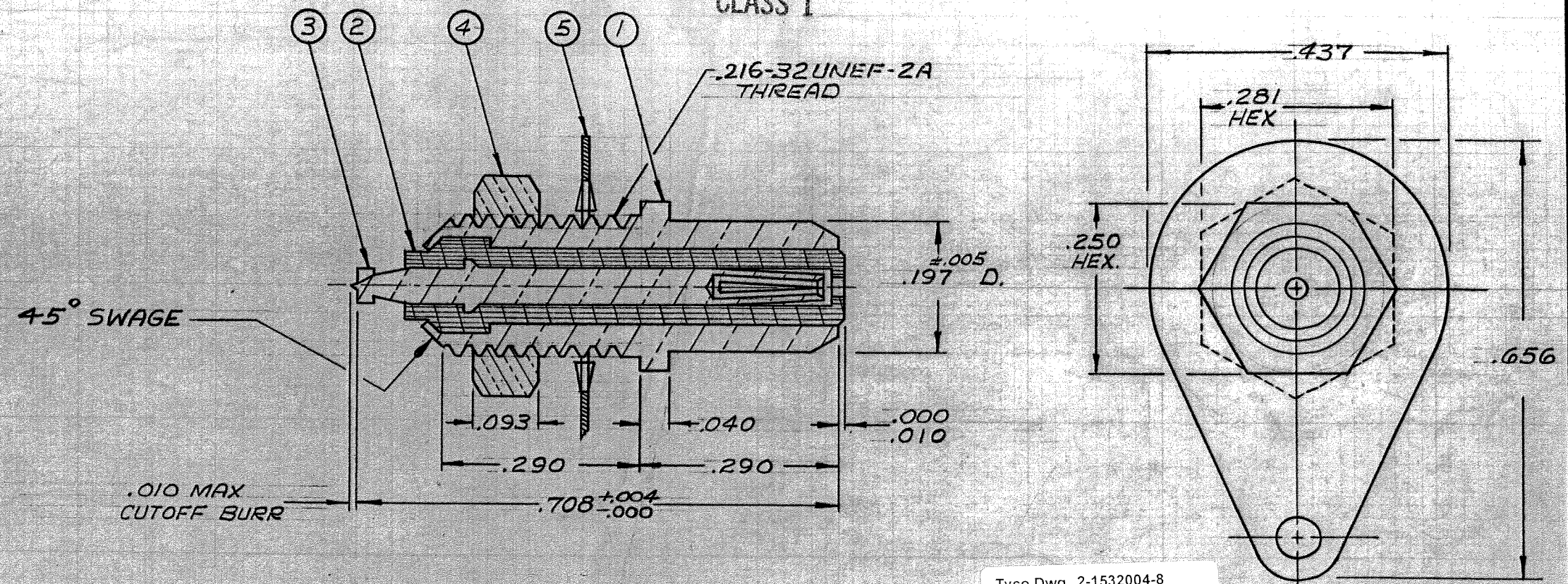

Tyco Dwg 2-1532004-8
Micro P/N 031-0049-0001

②	1	003-0304-0001	LOCK LUG	# 425 BRONZE ALLOY	⑤
②	1	003-0061-0001	HEX NUT	BRASS QQ-B-626	④
③	1	003-1302-0002	SOCKET	COPPER ALLOY	③
	1	003-1303-0001	INSULATOR	TEFLON PER L-P-403	②
②	1	003-1304-0001	HOUSING	BRASS QQ-B-626	①
	QUAN.	COMPONENT No.	NOMENCLATURE	MAT'L & SPEC.	CODE

- 5. INSULATION RESISTANCE - 5.0×10^3 MEGOHMS MIN.
- 4. WORKING VOLTAGE - 750 V.R.M.S.
- ③. GOLD PLATE PER MIL-G-45204, TYPE II, CLASS I
- ②. SILVER PLATE .0002 MIN PER QQ-S-365
- 1. THIS CONNECTOR MATES WITH ALL PLUGS IN SERIES SOS AS LISTED IN MALCO CATALOG

NOTES: UNLESS OTHERWISE SPECIFIED

T 386 29 UPDATE REV. DETON		2/19/88	STANDARD TOLERANCES UNLESS OTHERWISE SPECIFIED DEC. ± .010		MALCO A MICRODOT COMPANY, INC. 220 PASADENA AVE., SO. PASADENA, CALIF. 91030	
S 29718 UPDATE DWG		MC 7/18/88	FRAC. ±		SURFACE TREATMENT NOTED	
R 289 14 MAT'L OF ITEM # 5 WAS: PHOSPHOR BRONZE. YC		7/18/88	ANGLES ±		MATERIAL NOTED	
P 16000 REV. LETTER UP-DATED		7/18/88	ECCENTRICITY MAX. T.I.R.		APP greg g.	
N 6015 COMPONENT PART NUMBERS UPDATED. ADDED NOTE B.		EJ 3/16/88	HOLE DIA. ±		APP 1280	
M 5636 DIM. .000-.010 WAS .000-.005		J.N. 1/18/87	SURFACE ROUGHNESS MICRO INCHES		CHECKED BY	
L 5 4 5 0 003-1304-01 WAS 003-0233 003-1303 WAS 003-0339 003-1302 WAS 003-0247 SOCKET MAT'L WAS COIN SILVER REVISED & REDRAWN, ADDED CODE CDM.		J.N. 11/29/86	THREADS TO MIL-S-7742 COMMERCIAL TOLERANCES APPLY TO STOCK DIMENSIONS		DRAWN BY G.S.	
ASSEMBLY NO REQ'D	LET ECO	REVISION DESCRIPTION	BY CK	DATE	APP	SCALE WT DATE
NEXT ASSEMBLIES						4-3-62
BULKHEAD RECEPTACLE				CODE CDM		DRAWING NUMBER 031-0049-0001 T

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[2-1532004-8](#)