

REV. B  
DCO 300860


TOLERANCES ±.010" - UNLESS  
OTHERWISE SPECIFIED

COIL: @ 25°C  
RESISTANCE 320 OHMS ±10%  
NOMINAL VOLTAGE 28 VDC  
MUST OPERATE 13.5 VDC MAX.  
COIL TRANSIENT SUPPRESSION: 42 VDC MAX.  
MUST RELEASE 5.5 VDC MAX., 2.3 VDC MIN.

ENVIRONMENT:  
VIBRATION 10 Hz TO 3000 Hz @ 30 g's  
SHOCK 200 g's 6 MS. DURATION  
TEMPERATURE -70 °C TO +125 °C

NOTES: OPERATE, RELEASE 10 MS MAX.  
CONTACT BOUNCE 1 MS MAX.  
CONTACT BREAK BOUNCE 0.1 MS MAX.

## CUSTOMER DATA SHEET

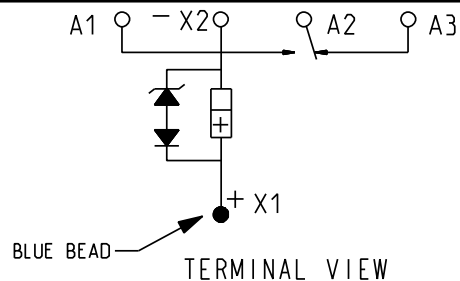

CONTACT RATING:  
25 AMPS 28 VDC, 115 VAC 400 Hz RESISTIVE  
50,000 OPERATIONS

DR. B.D. 21MAY2008 CK. J.M.B. 5/21/08

**Tyco Electronics**

©COPYRIGHT 2005  
TYCO ELECTRONICS CORPORATION  
ALL INTERNATIONAL RIGHTS RESERVED

CUST. QPL  
CUST. NO. M6106/19-024 REV. ----

TE NUMBER  
3-1617748-0

CII PART NUMBER

FCA-125-24

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TE Connectivity:](#)

[3-1617748-0](#)